




ENGLISH

Datasheet

Stock No: 522-660

RS Pro 5 Core YY Control Cable Unscreened Polyvinyl Chloride PVC Sheath

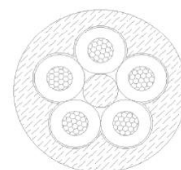

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.25 \pm 0.008 \times 30$

Insulation: PVC

Insulation Dia. (mm): $2.8 \pm 0.1 \times 5C$

Filler 1: 2.0 PVC Strip

Filler 2: Chalk

Jacket: PVC

Outer Dia. (mm): 9.2 ± 0.25

Colour:

The colour of the insulation: Black
x 4 , Yellow/Green

The jacket colour: Grey (RAL-7001)

Marking(3times/m):

RS 522660 YY/NR 5 Core x 1.5mm²

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω /Km) :
<13.7

Min.Insulation DC Resistance at 20°C ($M\Omega \cdot KM$) :
>500

Current Rating : 16 A