
 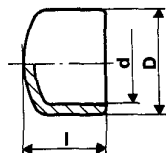


21 96 01


Caps, PVC-U



d	PN	Code	£	SP	GP	a		D	I		
12	16	721.960.104	0.52	10	500	4		19	15		
16	16	721.960.105	0.58	10	100	6		22.5	21		
20	16	721.960.106	0.70	10	100	8		26.5	23.5		
25	16	721.960.107	0.83	10	100	13		32.5	28		
32	16	721.960.108	0.93	10	100	21		40	32		
40	16	721.960.109	1.45	10	100	30		47	38		
50	16	721.960.110	2.45	10	100	51		58.5	45		
63	16	721.960.111	3.00	5	50	100		73.5	55.5		
75	16	721.960.112	7.25	5	50	155		87	65		
90	16	721.960.113	9.20	5	5	270		105	77		
110	16	721.960.114	14.20	5	5	640		127.5	94		
140	10	721.960.116	24.40	2	14	990		164	92		
160	10	721.960.117	34.30	2	2	1500		188	130		

21 70 05

Blanking Flanges, PVC-U

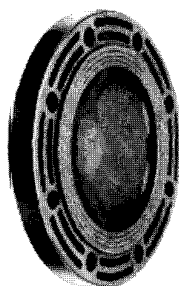

d	PN	Code	£	SP	GP	g	D	a	k	f	b	l	h	AL
225		721.700.520	55.00	1	1	2600	340	273	295	213	36	22	63	8
250		721.700.521	67.00	1	1	3200	370	303	325	238	36	22	63	8
280		721.700.522	80.00	1	1	4650	395	328	350	266	36	22	65	12
315		721.700.523	97.00	1	1	5750	445	378	400	299	36	22	65	12
355		721.700.524	110.00	1	1	6800	505	430	460	341	38	22	67	16
400		721.700.525	118.00	1	1	9000	565	482	515	384	42	26	71	16