


**Item # 70-750EL8-1, 70-750EL8-1 Socket / 16 Amp Rating, 300 Volts**

8 Pin Octal, Logic Style, Finger Safe, DIN/Panel Mount with Elevator Terminals, Module Compatible

This Item is Normally Stocked

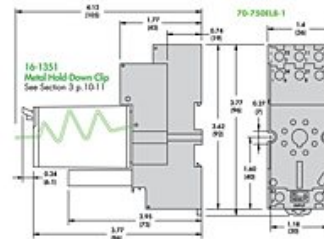

[Specifications](#) · [Electrical Rating](#) · [Temperature](#) · [Construction](#) · [Miscellaneous](#) · [Product Certifications](#)

**Specifications**

|                       |   |
|-----------------------|---|
| Check Inventory       | <a href="#">Check Distributor Inventory</a> |
| Contact Configuration | DPDT  |
| Number of Terminals   | 8   |
| Mounting Style        | DIN Rail<br>Panel                           |

**Electrical Rating**

|                        |       |
|------------------------|-------|
| Current Rating         | 16 A  |
| Nominal Voltage Rating | 300 V |

**Temperature**

|               |                  |
|---------------|------------------|
| Storage Range | - 40 to + 105 °C |
|---------------|------------------|

**Construction**

|                                   |                             |
|-----------------------------------|-----------------------------|
| Protection Category (Finger Safe) | IP 20                       |
| Internal Metal Tracks             | Copper Alloy<br>Zinc Plated |
| Terminals                         | Steel<br>Zinc Plated        |
| Screw Style                       | Combination Head            |
| Screw Size                        | M3.5 mm                     |
| Screw Torque 3.5 mm (Maximum)     | 9 / 1.0 Lb-in / Nm          |
| Terminal Connection               | Elevator                    |
| Terminal Layout                   | Logic                       |
| Base                              | Octal                       |

**Miscellaneous**

|   |  |
|---|--|
| Wire Size Capacity (Maximum), EN 60204-1, Soid Cu | 12 / 14 (2) AWG, 4 / 2.5 (2) mm <sub>2</sub> |
|---|--|

|  |  |
|--|--|
| <b>Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu</b> | 12 / 14 (2) AWG, 4 / 2.5 (2) mm <sub>2</sub> |
| <b>DIN Rail Mounting, EN 60715</b>                           | 35 mm  |
| <b>Chassis Mount Screw Torque</b>                            | 7 / 0.8 Lb-in / Nm                           |
| <b>Flammability Rating</b>                                   | 94V-0 Class                                  |
| <b>Body Color</b>  | Light Gray                                   |
| <b>DIN Locking Method</b>                                    | Red Plastic Locking Clip                     |

---

**Product Certifications**

|                         |                         |
|-------------------------|-------------------------|
| <b>Agency Approvals</b> | CE<br>RoHS<br>UL<br>CSA |
|-------------------------|-------------------------|