


Datasheet

RS 12 Core Unscreened Industrial Cable, PVC Sheath, 440 V, 6.4mm OD, 0.22 mm² CSA 1 A, 100m

Stock Number - 660-4068

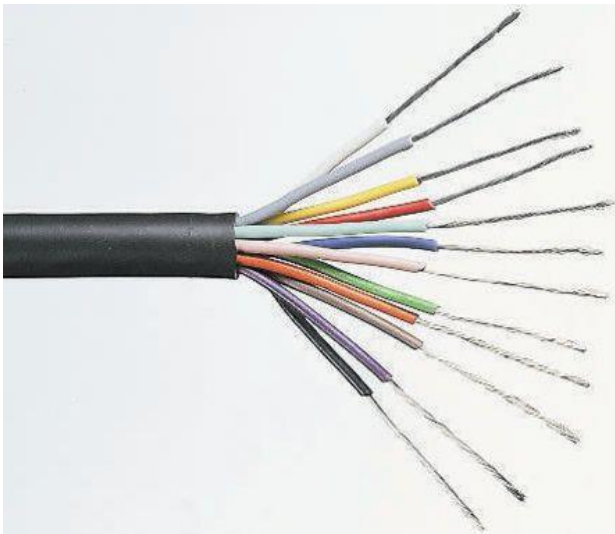

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):440

Flammability Test: IEC60332-1



ENGLISH

Construction:

Conductor: Tinned Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 7$

Insulation: PVC

Insulation Dia. (mm): $1.2 \pm 0.05 \times 12C$

Tape: Mylar Spiral

Coverage: $\geq 115\%$

ID Thread : Green, White/Green

A rip cord : 210 D

Jacket: FR-PVC

Outer Dia. (mm): 6.1 ± 0.1

Colour:

The colour of the insulation: Red , Blue

, Green , Yellow ,

White , Black , Brown , Violet , Orange ,

Pink , Light Green ,

Grey

The jacket colour: Black

Marking(3times/m):

RS 6604068 7 - 2 - 12A

Performance:**Electrical Characteristics:**

Max.Conductor DC Resistance at 20°C (Ω /Km) :
<92

Min.Insulation DC Resistance at 20°C ($M\Omega$ *KM) :
>200

Current Rating : 1 A

