



### Polyethylene Spiral Binding for enhanced flame protection

- SBPEFR

SBPEFR spiral binding is used in areas, where fire protection is important in the automotive and electrical industry.

#### Features and Benefits

- Organises and protects cables and hoses
- Self-extinguishing according to UL94 V2
- Suitable for retro-fitting
- Cables branch out at any point
- Wide range of diameters and colours




Spiral binding SBPEFR is available in a wide range of diameters and in colours black and white.

Spiral binding made of standard polyethylene can be found in the Product Catalogue.

<b>MATERIAL</b>	Polyethylene (PEFR), Flame retardant
<b>Operating Temperature</b>	-60 °C to +80 °C, intermittent +120 °C
<b>Flammability</b>	UL94 V2, FMVSS 302, Type B

RoHS

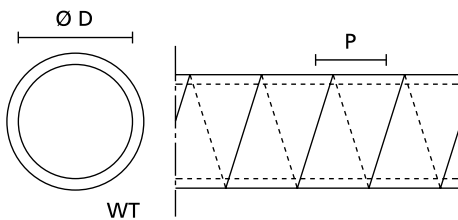

One Step to the Web!

TYPE	Nominal Ø	Wall (WT)	Pitch (P)	Bundle Ø min.	Bundle Ø max.	Colour	Reel Length	Article-No.
SBPEFR1.5	1.5	0.8	6.0	1.6	8	Black (BK)	30 m	161-43001
	1.5	0.8	6.0	1.6	8	White (WH)	30 m	161-43000
SBPEFR4	4	1.0	7.8	5	20	Black (BK)	30 m	161-43101
	4	1.0	7.8	5	20	White (WH)	30 m	161-43100
SBPEFR9	9	1.4	12.5	10	100	Black (BK)	30 m	161-43201
	9	1.4	12.5	10	100	White (WH)	30 m	161-43200
SBPEFR16	16	1.6	16.0	20	150	Black (BK)	30 m	161-43301
	16	1.6	16.0	20	150	White (WH)	30 m	161-43300

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content.