

Clip, 5 x 20 mm, Version 1



500 V · 10 A (UL/CSA)



Description

- Through hole mounting
- Tape & Reel for automatic pick & place

Approvals

- UL File Number: E39328

Weblinks


[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [REACH](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [Detailed request for product](#)

Technical Data

Fuse-Link	5 x 20 mm
Mounting	PCB
Terminal	Solder THT
Rated Voltage	500 V (UL/CSA)
Rated current	10 A (UL/CSA)
Admissible Ambient Air Temp.	-40 °C to 90 °C
Material: Terminals	see variants
Unit Weight	0.32 g
Storage Conditions	0 °C to 60 °C, max. 70% r.h.
Product Marking	none

Soldering Methods	Wave
Solderability	245 °C / 3 sec acc. to IEC 60068-2-20, Test Ta, method 1
Resistance to Soldering Heat	260 °C / 10 sec acc. to IEC 60068-2-20, Test Tb, method 1A
Contact Resistance	< 10 mΩ at 20 mV

Dimension

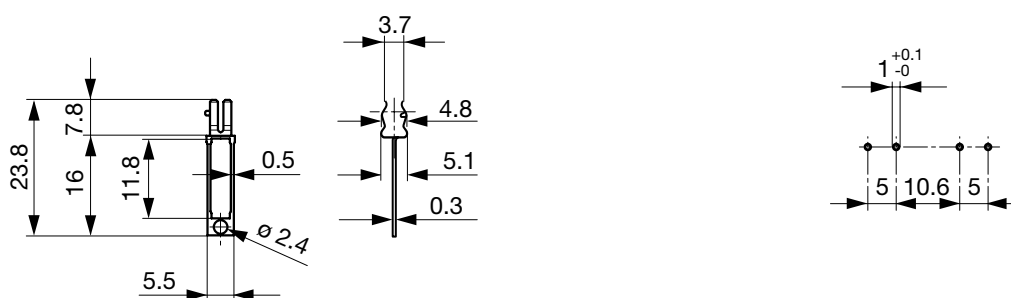

Drilling diagram

All Variants

Clip	Terminal	Material: Terminals	Order Number
•	Straight	Silver-Plated Bronze	0752.1242
•	Straight	Nickel-Plated Bronze	0752.1243

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>

Packaging Unit

Taped reeled (1000 pcs.)