

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130070-0023](#)
Status: **Active**
Overview: Brad® Quick-Change® Connectors
Description: Quick-Change® Female Field Attachable, 4 Pole, Straight

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Field Attachable / Accessories
 Series [130070](#)
 IP Rating IP67
 Overview [Brad® Quick-Change® Connectors](#)
 Product Name Quick-Change®
 Type Field Attachable Connector
 UPC 78678804605

Physical

Cable Diameter N/A
 Coupling Type Internal Thread
 Diagnostics / LEDs No
 Diagnostics Port No
 Gender Female
 Keyway Single
 Material - Connector Body PVC
 Material - Contact Copper
 Material - Coupling Nut Anodized Aluminum
 Material - Plating Mating Gold over Copper
 Net Weight 132.500/g
 Orientation Straight
 Poles 4
 Temperature Range - Operating -20°C to +90°C
 Wire Size AWG N/A

Electrical


Current - Maximum per Contact 30A
 Voltage - Maximum 600V DC

Material Info

Old Part Number CA4000-39

Reference - Drawing Numbers

Sales Drawing SD-120336-001

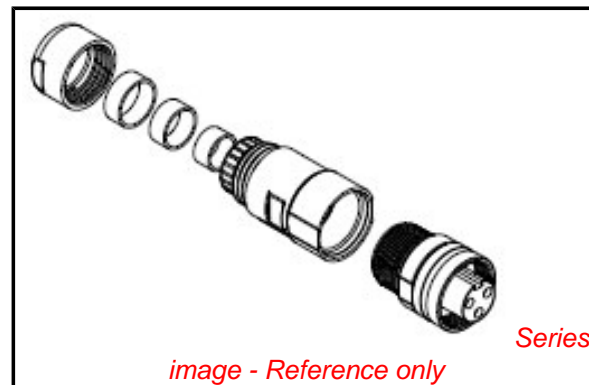

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

130070Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION