

VG95328 Z1 A, B, and C
Receptacle Covers for Panel Attachment
For Connectors A to H and P, R, S and T Only

VG95328

Z1


A

18


Receptacle
Cover

Lanyard Style
A = Chain with
Eyelet
B = Rope with
Eyelet
C = Rope Sans
Eyelet


Shell Size

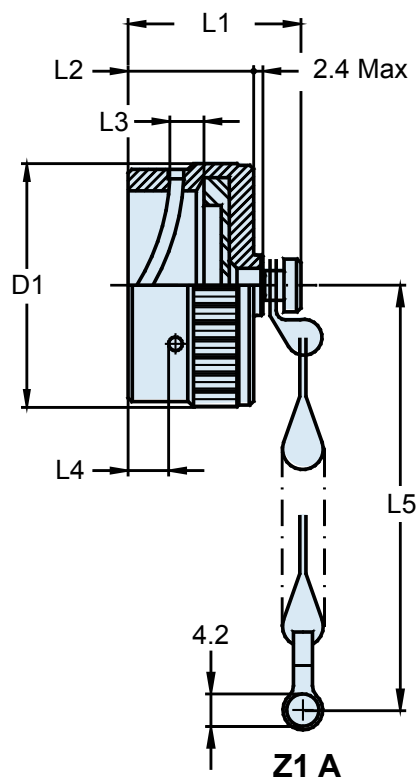

Z1 A

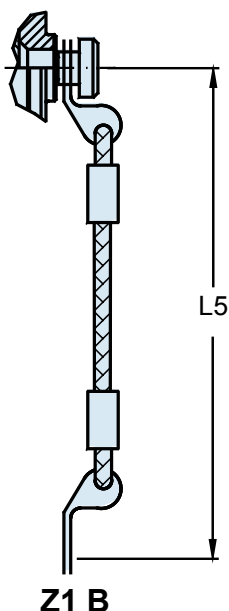

Z1 B

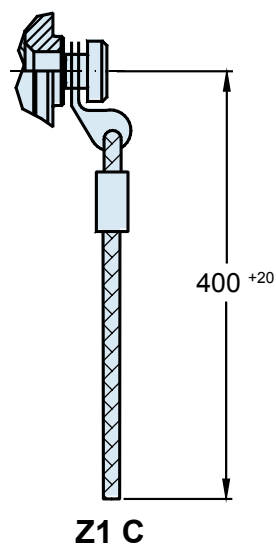

Z1 C

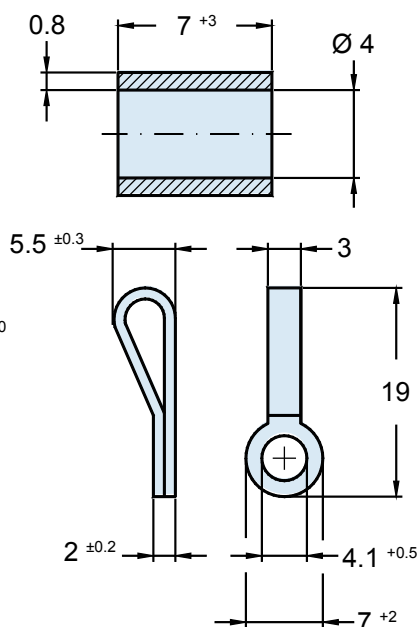


TABLE I: DIMENSIONS

Shell size	D1 Max.	L1 Max.	L2 Max.	L3 + 0.25 - 0.38	L4 Max.	L5 + 13 - 7	Maximum Weight in Grams
8	18.7	21.5	14.3	2.92	3.78	77	17
10	21.9	21.5	14.3	2.92	3.78	77	17
12	25.4	21.5	14.3	2.92	3.78	89	25
14	28.6	21.5	14.3	2.92	3.78	89	25
16	31.8	21.5	14.3	2.92	3.78	89	29
18	35.0	21.5	14.3	2.92	3.78	89	29
20	38.1	21.5	14.3	2.92	3.78	102	33
22	41.3	21.5	14.3	2.92	3.78	102	36
24	44.5	22.3	15.3	3.73	2.21	102	42

VG95328 Z2 A, B, and C
Plug Covers for Panel Attachment
For Connectors J to N and U, V and W Only



VG95328
Accessories

VG95328

Z2


A

18


Plug
Cover

Lanyard Style
A = Chain with
 Eyelet
B = Rope with
 Eyelet
C = Rope Sans
 Eyelet


Shell Size

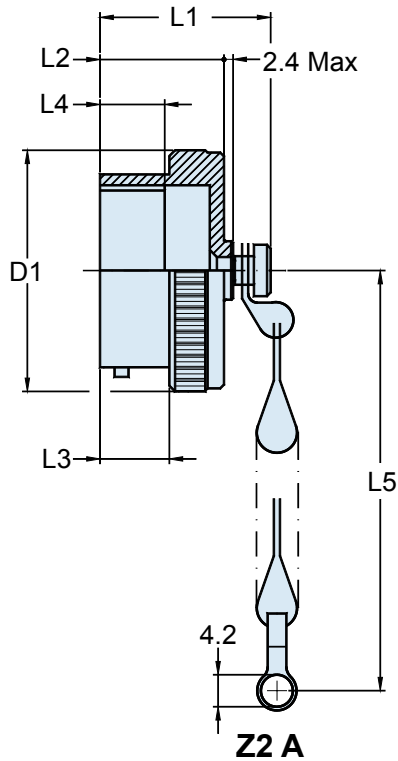

Z2 A

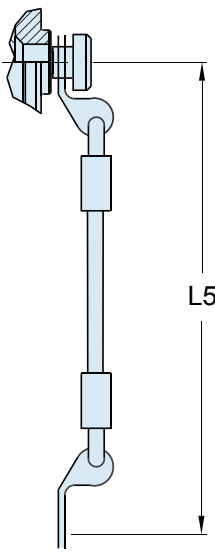

Z2 B

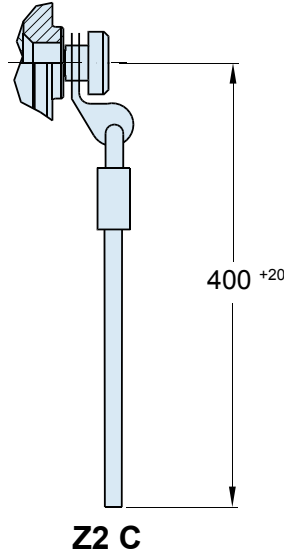

Z2 C

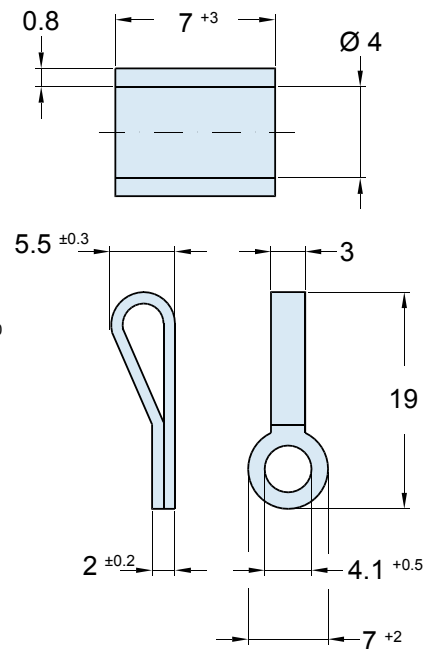


TABLE I: DIMENSIONS

Shell size	D1 Max.	L1 Max.	L2 Max.	L3 + 0.8 - 0	L4 + 0.25 - 0.5	L5 + 13 - 7	Maximum Weight in Grams
8	18.3	19.9	14.3	9.35	8.3	77	17
10	21.5	19.9	14.3	9.35	8.3	77	17
12	25.4	19.9	14.3	9.35	8.3	89	21
14	28.6	19.9	14.3	9.35	8.3	89	24
16	31.8	19.9	14.3	9.35	8.3	89	27
18	35.0	19.9	14.3	9.35	8.3	89	31
20	38.1	21.5	15.9	10.92	9.9	102	36
22	41.3	21.5	15.9	10.92	9.9	102	40
24	44.5	22.3	16.7	11.76	9.9	102	43