



Deep groove ball bearings, single row, seal on both sides

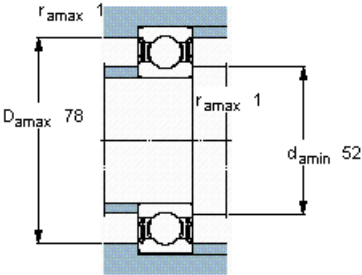

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
45	85	19	35,1	21,6	0,915	-	5000	0,41	6209-2RS1 *

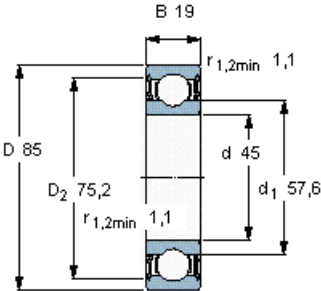

Calculation factors

k_f 0,025
 f_0 14