

NEW PRODUCT INFORMATION

San Ace 40 9HV type High Static Pressure Fan


SANYO DENKI EUROPE SA. is pleased to introduce its new **San Ace 40 9HV type** DC fan, measuring 40mm square by 28mm thick. This high static pressure fan has been designed to enhance the High Performance serie with higher static pressure and less power consumption than current models.



Product Features


- 1 High Static Pressure**
max. static pressure: 1,100Pa
- 2 Less Vibration**
up to 50% reduction in comparison with current model
- 3 High Reliability**
expected life time 40,000 hours at 60°C
- 4 PWM Speed Control Function**

How to read Model Number*

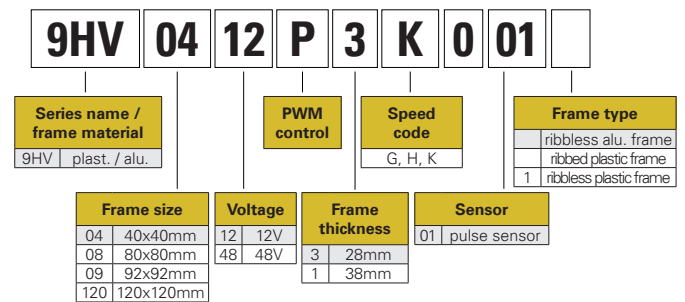


(*) contact us for available model numbers

9HV Product Range

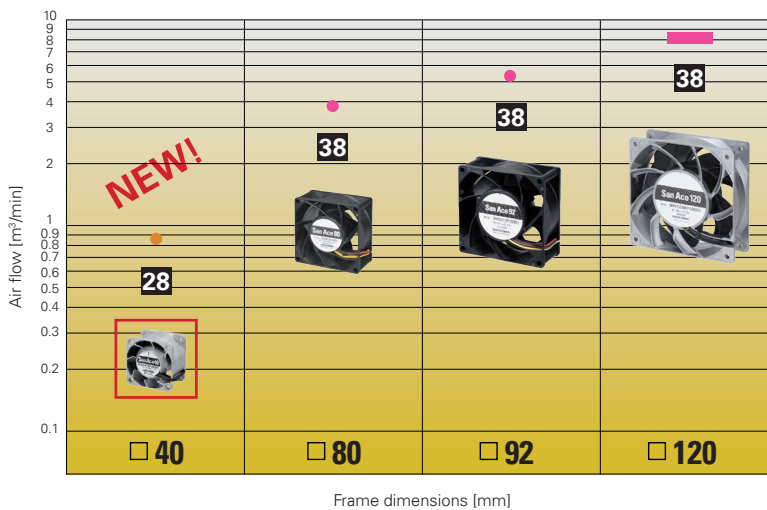

Performance Comparison

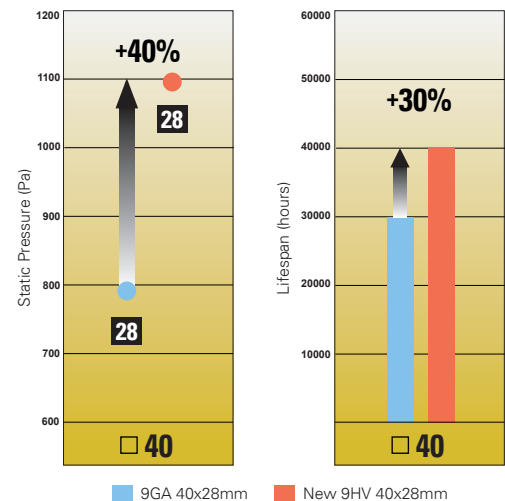

Main Specifications 9HV serie

- Size 4 sizes : 40, 80, 92 and 120mm by 2 thicknesses
- Air flow from 0.83 to 8.3m³/min - 29.3 to 293CFM
- Static pressure from 1,000 to 1,300Pa
- Rated voltage 12 or 48VDC depending on models
- Expected life time 40,000 hours at 60°C
- Speed control PWM (25kHz)
- Speed feedback pulse sensor

Target Applications

- IT, Telecommunication devices, Industry:
- Servers
 - Data storage systems
 - Optical amplifiers
 - Industrial inverters
 - Switching power supplies...

For further information on **high static pressure** DC fans, please contact us at **+33 1 48 63 26 61** or email us at **info@sanyodenki.eu**.