



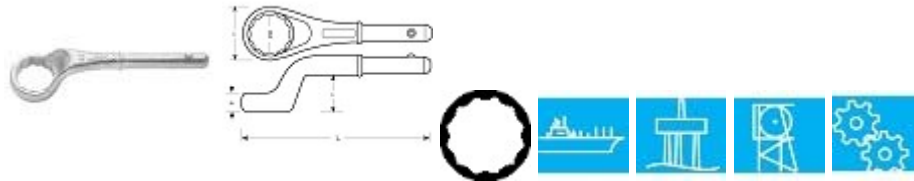
Heavy duty ring spanner, offset Metric, 310M




 

Finish: bright nickel and chrome-plated.

Material: CHROME-VANADIUM.

Tubular handle supplied seperatly.

Robust construction for work under very tough conditions.



					L mm	a mm	b h mm mm 
310M-24		1829612	1	24	180	17.0	38 29.5 380
310M-27		1829629	1	27	190	17.0	41 31.5 410
310M-30		1829636	1	30	200	18.0	48 33.5 510
310M-32		1829643	1	32	235	18.0	49 34.0 740
310M-36		1829650	1	36	245	20.0	54 35.5 780
310M-38		1829667	1	38	250	21.0	56 37.5 860
310M-41		1829674	1	41	265	22.0	62 39.5 980
310M-46		1829681	1	46	280	23.0	69 40.0 1280
310M-50		1829698	1	50	290	25.5	76 42.5 1400
310M-55		1829704	1	55	300	28.0	81 45.5 1570
310M-60		1829711	1	60	345	30.5	90 49.0 2340
310M-65		1829728	1	65	355	33.0	98 53.0 2580
310M-70		1829735	1	70	365	35.5	105 55.0 2800
310M-75		1829742	1	75	375	38.0	110 57.5 3050
310M-80		1829759	1	80	385	40.5	125 59.0 3900
310M-85		1829766	1	85	385	40.5	125 59.0 3900
310M-90		1829773	1	90	410	45.0	140 63.0 5000
310M-95		1829780	1	95	410	45.0	140 63.0 5000