

## Numeric Profibus Data Displays

- Compact 96 x 24 mm panel mount numeric unit
- Display Profibus-DP data inputs
- Cyclical data exchange with Profibus master
- 6 digit, 13 mm red LED display
- Rugged metal case
- IP65 front panel with supplied gasket
- 24 VDC supply
- Bus status LEDs and self test function




### Specifications


Display	Six 7-segment, 13 mm red LEDs
Interface	Profibus-DP (GSD file supplied)
Display characters	0 to 9 and H, E, L, P, - and Blank
Addresses	0 to 126
Baud rate	9600 Baud to 12 Mbaud
Front protection	IP65 with supplied gasket
Dimensions	96 x 24 mm, depth 60 mm
Panel cut-out	93 x 22.2 mm
Mounting	Screw clamps
Operating temperature	0 to +50 °C
Storage temperature	-25 to +70 °C
Power supply	24 VDC ± 20 %, 75 mA

### Application Example:

As Profibus-DP slaves in industrial control applications

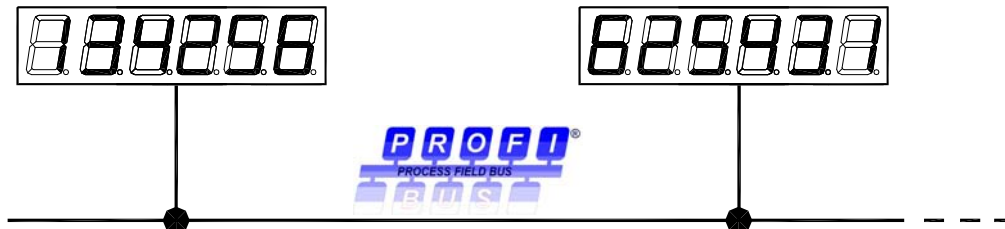

### Dimensions:

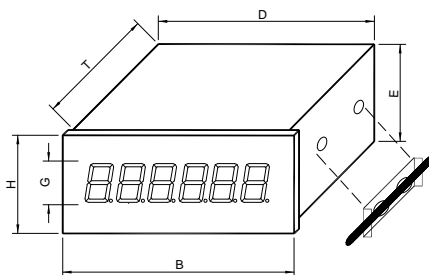

#### Also available:

- Numeric Serial data displays
- Alpha-Numeric Profibus and Serial data displays

Digits	Character height G	B	H	D	E	T
	mm	mm	mm	mm	mm	mm
6	13	96	24	91.5	20	60

### Stocked by RS Components Ltd

Description	Model	Part Number	RS Stock No.
6-digit Profibus-DP data display	MI-PAN-DP6R13	KPB1LE1-I8121462	711-6014

Mipan-DP\_GB1007