



Data Specification Sheet

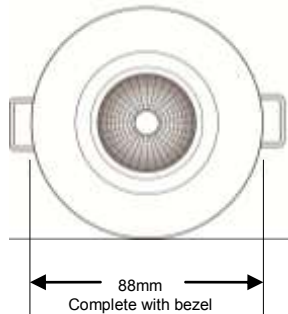

Shown with Bezel (not included)

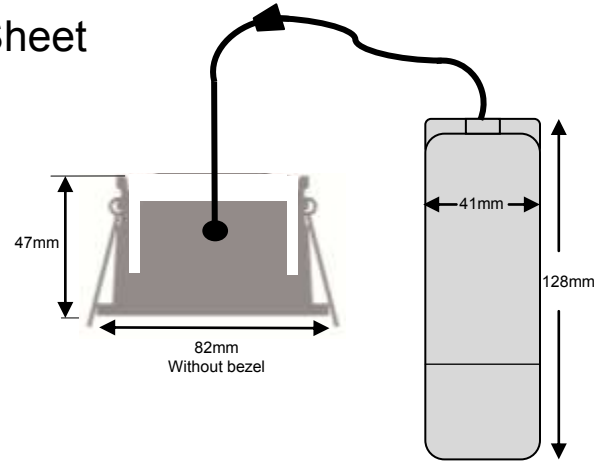

IP20 LED Fire Rated Tilt Downlight c/w Dimmable Driver

Description	IP20 LED Fire Rated Tilt Downlight c/w Dimmable Driver			
Code	851-2964 Warm White IP20 LED Fire Rated Tilt Downlight 851-2961 Cool White IP20 LED Fire Rated Tilt Downlight			
Code – Bezel Only	858-0967 Matt White Bezel	858-0951 Brass Bezel	858-0964 Chrome Bezel	
	858-0955 Brushed Chrome Bezel			
Bezel Diameter	88mm			
Rim Diameter	82mm			
Cut Out	72mm			
Minimum Depth (Void)	75mm			
Total length of driver lead	300mm			
Weight	0.36Kg			
Maximum Tilt Angle	25°			
Recommended product location	Indoor Outdoor			
Finishes available (Bezels sold separately)	Matt White, Brass, Chrome, Brushed Chrome			
Control Gear Type	8W 180mA SELV LED Dimmable Driver supplied pre-wired to downlight			
Lamp Supplied	Fixed non-replaceable 8W COB LED			
Class	Class II. Must not be Earthed			
IP	IP20			
Photometric Testing	Yes			
Lumen Output	460lm Warm White – 530lm Cool White			
Beam Angle	38°			
Dimmable	Yes			
Instruction sheet	Yes			
Origin of manufacture	China			
Main materials:				
• Chassis	Pressed Steel			
• Body	Die cast			
• Bezel	Die cast			
Method of fix	Twin fixed spring			
Electrical Connections	Loop in 10Amp L.N. + Earth Park Nylon Connector, Push-in Terminals			
CE mark	Yes			
Batch coding details on product	Yes			
Certificate of Conformity (Held on File)	Yes			
Manufactured in accordance	EN60598-1 General requirements EN60598-2-1 Fixed general purpose luminaires EN60598-2-2 Recessed luminaires Part P (Installation requirements) BS476 – Part 21 & Part 23 Fire rating			