


REV. B

DCO 300781

TOLERANCES $\pm .010''$ - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	320 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
	TRANSIENT SUPPRESSION - 42 VDC MAX.
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

CUSTOMER DATA SHEET

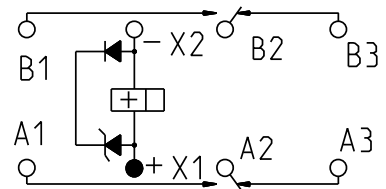

TERMINAL VIEW

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C
NOTES: OPERATE, RELEASE 10 MS MAX.	
CONTACT STABILIZATION 2.5 MS MAX.	
CONTACT BOUNCE 1 MS MAX.	
CONTACT BREAK BOUNCE 0.1 MS MAX.	

CONTACT RATING: LOW LEVEL
 TO 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE,
 100,000 OPERATIONS

DR. B.D. 05MAR2008 CK. 3/7/08 J.M.B.

Tyco Electronics ©COPYRIGHT 2005
 TYCO ELECTRONICS CORPORATION
 ALL INTERNATIONAL RIGHTS RESERVED

CUST. _____
 CUST. NO. M83536/10-023L REV. ---

TE NUMBER
 1-1617749-9

CII PART NUMBER
 FCA-210-1023L