


Product

AKL 1-g

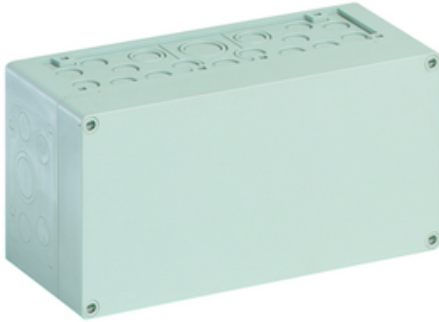

Entries

Entries end:

15 x M20

2 x M20/M25

1 x M32/M40

Entries on each side:

4 x M20

1 x M25/M32

Empty Enclosure, with attachment bushes, sealing and insulating plugs, base and cover: polystyrene, grey, similar to RAL 7035

Article: AKL 1-g

Technical Data

Dimensions:

Height: 132 mm

material:

Base: Polystyrene, grey, similar to RAL 7035

Cover: Polystyrene, grey, similar to RAL 7035

Sealing: Polyurethane

Cover screw: Polyamide 6, fiber-glass reinforced

Properties:

Ambient temperature (min.): -25 °C

Ambient temperature (max.): 40 °C

Ambient temperature (24 h): 35 °C

Max. rel. humidity at 25° C (short Therm): {50%}

Rated insulation voltage AC: 690 V

Impact resistance: IK07 acc. DIN EN 5012 / VDE 0470 Part 100

Halogen-free:	√
PVC-free:	√
Heavy metals-free:	√
Silicone-free:	√
UV resistance:	-
Combustion behaviour to UL:	HB acc. UL94
Combustion behaviour to VDE:	650°C acc. VDE 0471/ EN 60695
Knockouts:	√

Manufacturer

Günther Spelsberg GmbH + Co. KG
Im Gewerbepark 1
58579 Schalksmühle
+49 (0)2355/892-0
+49 (0)2355/892-299
www.spelsberg.de