

# FO connectors - VS-PPC-C1-SCRJ-MNNA-PG9-A4D-C - 1608032


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Fiber optic connector SCRJ, IP67, with push-pull interlocking, metal housing, duplex, with fast connection technology, for polymer fiber 980/1000 µm, for individual wire diameter 2.2 mm, for cable cross section 6.5 mm ... 9.5 mm



## Key commercial data

Packing unit	1 pc
GTIN	 4 046356 131704
Weight per Piece (excluding packing)	72.2 g
Custom tariff number	85366990
Country of origin	Germany

## Technical data

### Mechanical characteristics

Number of positions	2
Connection profile	SCRJ in acc. with IEC 61754-24
Locking type	Push Pull
Fiber type	Polymer Fiber
Ferrule diameter	2.50 mm
Insertion/withdrawal cycles	≥ 500
External cable diameter	6.5 mm ... 9.5 mm
Color	silver

### Ambient conditions

Ambient temperature (operation)	-40 °C ... 70 °C
Degree of protection	IP65/67

### Material data

Inflammability class according to UL 94	V0
Housing material	Zinc die-cast
Housing surface material	Nickel-plated
Material	Metal

# FO connectors - VS-PPC-C1-SCRJ-MNNA-PG9-A4D-C - 1608032

## Technical data

### Material data

Material, O-ring	NBR
Cable seal material	TPE
Material housing intermediate seal	NBR
Ferrule material	Copper alloy
Ferrule holder color	Blue

### Electrical characteristics

Number of positions	2
Pollution degree	2
Attenuation	≤ 1.5 dB (Insertion attenuation)

## Classifications

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260708
eCl@ss 7.0	27440312
eCl@ss 8.0	27440312

### ETIM

ETIM 3.0	EC001122
ETIM 4.0	EC001122
ETIM 5.0	EC001122

### UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

## Approvals

### Approvals

---

### Approvals

UL Listed / GOST / GOST

---

# FO connectors - VS-PPC-C1-SCRJ-MNNA-PG9-A4D-C - 1608032

## Approvals

Ex Approvals

---

Approvals submitted

---

## Approval details

UL Listed

GOST

GOST

## Accessories

Accessories

Assembly tool

FO accessories - VS-SCRJ-POF-KONFTOOL-POLISH - 1658820



SCRJ polishing tool set, for polymer fiber, for field assembly of the SCRJ connector (IP20/IP67) with fast connection technology, with stripping tool, diagonal cutter, aramid scissors, polishing materials, microscope, 2x SCRJ connector IP20

---

FO accessories - TF-SCRJ-POF KONF SET - 1405246



SCRJ cutting tool set, for polymer fiber, for field assembly of SCRJ/IP20 and SCRJ/IP67 push/pull connectors with fast connection technology, consisting of stripping tool, aramid scissors, SCRJ cutting tool, microscope

---

# FO connectors - VS-PPC-C1-SCRJ-MNNA-PG9-A4D-C - 1608032

## Accessories

FO accessories - VS-SCRJ-POF-POLISH - 1656673



Refilling set for VS-SCRJ-POF-KONFTOOL-POLISH, consisting of two polishing discs and a polisher

FO accessories - CUTFOX-SCRJ-POF - 1405247



SCRJ cutting tool, for polymer fiber, for field assembly of SCRJ/IP20 and SCRJ/IP67 push/pull connectors with fast connection technology

 
FO accessories - WIREFOX-PN POF - 1405249




Sheath stripping tool, for polymer fiber

## Drawings

Schematic diagram



Dimensioned drawing

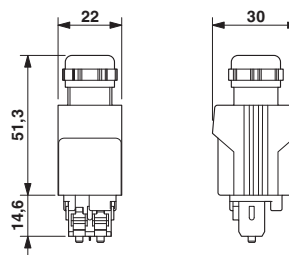

Push-Pull SCRJ connector IP65/67