

AUTOMATION & CONTROL

**Pan-Ty® Releasable Cable Ties — Weather Resistant Nylon 6.6**



- ▶ For Indoor or Outdoor Use
- ▶ Resists Damage Caused by Ultraviolet Light

Extended release tab permits easy release and re-use where changes are anticipated during development, production or servicing in the field.

**Standard Cross Section**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Package Quantity	PER PKG.
70043942	PRT1S-C0	1.00	4.8	0.190	100	30.96
70043938	PRT1.5S-C0	1.50	6.3	0.190	100	31.49
70043947	PRT2S-C0	1.88	7.4	0.190	100	36.04
70043951	PRT3S-C0	3.00	11.5	0.190	100	61.68
70043955	PRT4S-C0	4.00	14.5	0.190	100	73.68

**Light-Heavy Cross Section**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Package Quantity	PER PKG.
70043945	PRT2H-L0	2.00	8.4	0.300	50	42.30
70043949	PRT3H-L0	3.00	11.4	0.300	50	50.82
70043953	PRT4H-L0	4.00	14.5	0.300	50	61.92
70044523	PRT4H-TL0	4.00	14.5	0.300	250	243.37

ENCLOSURES

POWER

TUBING & SLEEVING

**Pan-Ty® Releasable Lashing Ties — Weather Resistant Nylon 6.6**



- ▶ For Indoor or Outdoor Use
- ▶ Resists Damage Caused by Ultraviolet Light
- ▶ Can Be Used with Mounting Clip (MCEH-S25-C0)

Release tab permits easy release and re-use where changes are anticipated during development, production or servicing in the field.

**Extra-Heavy Cross Section**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Package Quantity	PER PKG.
70043943	PRT2EH-Q0	2.00	9.0	0.500	25	30.73
70043956	PRT5EH-Q0	5.00	20.1	0.500	25	49.12
70043957	PRT6EH-Q0	6.00	22.2	0.500	25	57.38
70043958	PRT8EH-Q0	8.00	28.3	0.500	25	79.85
70043939	PRT10EH-Q0	10.00	34.2	0.500	25	91.42
70043940	PRT12EH-Q0	12.00	40.1	0.500	25	102.06

TEST & MEASUREMENT

PASSIVE & ACTIVE

**Pan-Ty® Releasable Cable Ties — Nylon 6.6**



For indoor use. Extended release tab permits easy release and re-use where changes are anticipated during development, production or servicing in the field.

**Standard Cross Section**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Package Quantity	PER PKG.
70043941	PRT1S-C	1.00	4.8	0.190	100	27.93
70044518	PRT1S-M	1.00	4.8	0.190	1000	142.00
70043937	PRT1.5S-C	1.50	6.3	0.190	100	28.09
70044517	PRT1.5S-M	1.50	6.3	0.190	1000	143.12
70043946	PRT2S-C	1.88	7.4	0.190	100	35.65
70044520	PRT2S-M	1.88	7.4	0.190	1000	143.68
70043950	PRT3S-C	3.00	11.5	0.190	100	57.54
70044521	PRT3S-M	3.00	11.5	0.190	1000	362.34
70043954	PRT4S-C	4.00	14.5	0.190	100	73.44
70044524	PRT4S-M	4.00	14.5	0.190	1000	420.90

**Light-Heavy Cross Section**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Package Quantity	PER PKG.
70043944	PRT2H-L	2.00	8.4	0.300	50	38.59
70044519	PRT2H-TL	2.00	8.4	0.300	250	160.17
70043948	PRT3H-L	3.00	11.4	0.300	50	47.26
70043952	PRT4H-L	4.00	14.5	0.300	50	47.77
70044522	PRT4H-TL	4.00	14.5	0.300	250	212.00

OPTOELECTRONICS

ASSEMBLY

INDEX

**Pan-Ty® Lashing Ties — Weather Resistant Nylon 6.6**




- ▶ For Indoor or Outdoor Use
- ▶ Resists Damage Caused by Ultraviolet Light
- ▶ Can Be Used with Mounting Clip (MCEH-S25-C0)

**Extra-Heavy Cross Section**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Package Quantity	PER PKG.
70043866	PLT2EH-Q0	2.00	9.0	0.500	25	30.73
70043906	PLT5EH-Q0	5.00	20.1	0.500	25	52.12
70043913	PLT6EH-Q0	6.00	22.2	0.500	25	57.93
70043922	PLT8EH-Q0	8.00	28.3	0.500	25	80.62
70043847	PLT10EH-Q0	10.00	34.2	0.500	25	91.42
70043849	PLT12EH-Q0	12.00	40.1	0.500	25	102.06

**Pan-Ty® Clamp Ties**

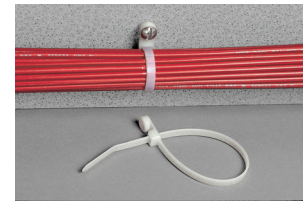

Natural nylon 6.6 for indoor use. For outdoor use, weather resistant material has greater resistance to damage caused by UV light or high temperature (85°C) applications.

- ▶ Secure a Cable Bundle to Control Panels, Communication Racks, Walls or Ceilings
- ▶ Allows for Bundling Before or After Screwing Clamp in Place
- ▶ All Cable Tie Cross Sections Have a Curved Tip That is Easier to Pick Up From Flat Surfaces, Allows Faster Initial Threading and Speeds Installation

**Miniature Cross Section Natural Nylon 6.6**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Screw Size	Package Quantity	PER PKG.
70043812	PLC1M-S4-C	0.75	4.3	0.100	M2.5	100	27.51
70044500	PLC1M-S4-M	0.75	4.3	0.100	M2.5	1000	230.39

**Intermediate Cross Section Natural Nylon 6.6**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Screw Size	Package Quantity	PER PKG.
70043811	PLC1.5I-S8-C	1.25	6.1	0.135	M4	100	27.68
70044499	PLC1.5I-S8-M	1.25	6.1	0.135	M4	1000	228.29

**Standard Cross Section Natural Nylon 6.6**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Screw Size	Package Quantity	PER PKG.
70043818	PLC2S-S6-C	1.84	7.9	0.190	M3	100	29.68
70044503	PLC2S-S6-M	1.84	7.9	0.190	M3	1000	226.02
70043816	PLC2S-S10-C	1.84	7.9	0.190	M5	100	30.63
70044502	PLC2S-S10-M	1.84	7.9	0.190	M5	1000	213.46
70043819	PLC3S-S10-C	3.00	12.0	0.190	M5	100	70.69
70044504	PLC3S-S10-M	3.00	12.0	0.190	M5	1000	381.31
70043821	PLC4S-S10-C	4.00	15.0	0.190	M5	100	79.93
70044506	PLC4S-S10-M	4.00	15.0	0.190	M5	1000	524.04

**Light-Heavy Cross Section Natural Nylon 6.6**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Screw Size	Package Quantity	PER PKG.
70043814	PLC2H-S25-L	2.00	9.0	0.300	M6	50	38.65
70044501	PLC2H-S25-TL	2.00	9.0	0.300	M6	250	148.98
70043820	PLC4H-S25-L	4.00	15.1	0.300	M6	50	45.36
70044505	PLC4H-S25-TL	4.00	15.1	0.300	M6	250	205.78

**Weather Resistant Nylon 6.6**

Stock No.	Mfr.'s Type	Max. Bundle Dia. (In.)	Length (In.)	Width (In.)	Screw Size	Package Quantity	PER PKG.
70043817	PLC2S-S10-C0	1.84	7.9	0.190	M5	100	36.74
70283168	PLC2S-S10-M0	1.84	7.9	0.190	M5	1000	302.23