

## FO PCB terminal block - FOPT 2,2-T - 1907911

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)




PCB terminal block, Pitch: 10.16 mm, Number of positions: 1, Connection method: Spring-cage connection, Mounting: Soldering, Conductor/PCB connection direction: 0 °, Color: green, Green housing with transmit diode/ optic fibers can be connected: Polymer fiber (in acc. with IEC 60793-2 type A4a, diameter outer sheath 2.2 mm) / data rate: 125 Mbps / transmission distance max. 50 m / detailed data sheet available on request

### Why buy this product

- Connection without fiber pretreatment, easy cutting using IBS RL FOC fiber cutter
- Bend protection sleeve supplied as standard
- Stability thanks to additional strain relief
- More user friendly thanks to direct plug-in technology with release button
- Integrated transmit and receive diode



### Key commercial data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 017918 606237
Weight per Piece (excluding packing)	3.64 g
Custom tariff number	85369010
Country of origin	Germany

### Technical data

#### Dimensions

Pitch	10.16 mm
-------	----------

#### General

Range of articles	FOPT
Connection in acc. with standard	EN-VDE
Nominal cross section	0 mm <sup>2</sup>
Solder pin surface	Sn
Inflammability class according to UL 94	HB
Number of positions	1

# FO PCB terminal block - FOPT 2,2-T - 1907911

## Classifications

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260704
eCl@ss 7.0	27440402
eCl@ss 8.0	27440402

### ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC002637
ETIM 5.0	EC002643

### UNSPSC

UNSPSC 6.01	30211832
UNSPSC 7.0901	39121429
UNSPSC 11	39121429
UNSPSC 12.01	39121429
UNSPSC 13.2	39121429

## Approvals

### Approvals

---

Approvals

GOST / GOST

---


Ex Approvals

---

Approvals submitted

---

### Approval details

GOST 
--

## FO PCB terminal block - FOPT 2,2-T - 1907911

### Approvals



### Accessories

Accessories

Assembly tool

Fiber cutter - IBS RL FOC - 2725147



Fiber cutter for assembling polymer fiber cables for connecting INTERBUS Ruggedline devices

---

### Data cable by the meter

FO cable - PSM-LWL-KDL-980/1000 - 2799283



Polymer fiber cable, duplex 980/1000  $\mu\text{m}$ , light-weight version for indoor installation, by the meter, without connector

---

FO cable - PSM-LWL-KDHEAVY-980/1000 - 2744319



Polymer fiber cable, duplex 980/1000  $\mu\text{m}$ , medium-weight version for permanent indoor installation, by the meter, without connector

---

FO cable - PSM-LWL-RUGGED-980/1000 - 2744322



Polymer fiber cable, duplex, 980  $\mu\text{m}$ /1000  $\mu\text{m}$ , heavy version for permanent indoor installation, sold by the meter without connectors

# FO PCB terminal block - FOPT 2,2-T - 1907911

## Accessories

FO cable - PSM-LWL-RUGGED-FLEX-980/1000 - 2744335



Polymer fiber cable, duplex 980/1000  $\mu\text{m}$ , heavy-weight, highly flexible version for flexible conduit applications, by the meter, without connector

## Screwdriver tools

Screwdriver - SZF 0-0,4X2,5 - 1204504




Actuation tool, for ST terminal blocks, also suitable for use as a bladed screwdriver, size: 0.4 x 2.5 x 75 mm, 2-component grip, with non-slip grip

Accessories - KST-POF - 1933011


Bend protection sleeve

## Drawings

Drilling diagram

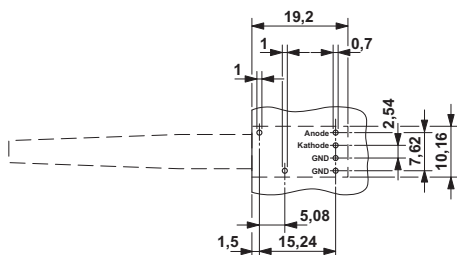


Dimensioned drawing

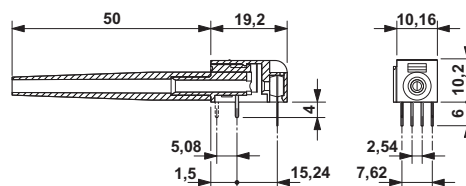

# FO PCB terminal block - FOPT 2,2-T - 1907911

Circuit diagram

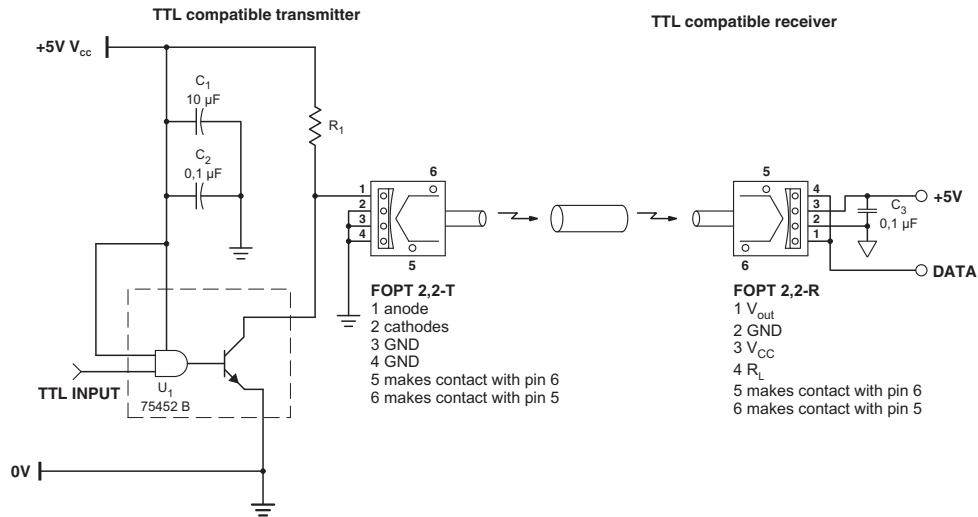

Block diagram

