

# M 228-V0



Euromas  
Enclosures, polycarbonate V0

**Order no.: 02228094**

## Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request

## Protection class


Depending on the model: IP 65 or IP 66/DIN EN 60529; IP 67 available on request for some sizes.

## Enclosure material

ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request), seal made of CR; for details see Technical Information

Scope of delivery: Lid and base, lid screws made of V2A, self-tapping screws for mounting bosses

Note: V0 = version in UL 94 V0 enclosure material.  
IP = Ingress protection acc. to DIN EN 60529

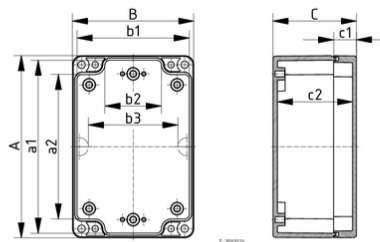

<b>A</b>	122 mm
<b>B</b>	120 mm
<b>C</b>	105 mm
<b>a1</b>	115 mm
<b>a2</b>	96,2 mm
<b>b1</b>	113 mm
<b>b2</b>	76,2 mm
<b>c1</b>	35 mm
<b>c2</b>	98,5 mm

## Technical drawings

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[02228094\\_M-228-V0-G.dxf](#) (318 KB)

Catalogue drawing in PDF format:

[02228094\\_M-228-V0.pdf](#) (92 KB)

## Chapter download

[Euromas ABS PC GB.pdf](#) (338 KB)

## Accessories



**Mounting plates, laminated paper (Pertinax), galvanised steel for version 260**

22000500

[M](#)

For EM/ET 217, EM/ET 227, M/T 217, M/T 227-228



**Rubber feet, plug-in**

22003300

[E](#)

For M/T 208-260



**Silicone seal for lid**

22003700

[SIL](#)

For M/T 217, M/T 227-228



**Wall brackets on rear, screw-on, polycarbonate**

22004900

[WL](#)

For M/T 210-243, M/T 246-253




**DIN rails DIN EN 60715 TH 15**

22001900

[TS 15](#)

For M/T 215-217, M/T 226-230

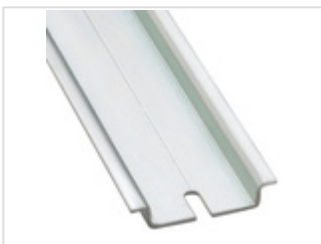

**DIN rails DIN EN 60715 TH 35**

22001910

[TS 35](#)

For M/T 215-217, M/T 226-230



**Threaded inserts for mounting bosses**

59002810

[DODGE M3x6,5](#)

ND = 4.0 x 6.5



59002820

[DODGE M4x9,5](#)

ND = 5.4 x 9.5



**Set of hinges**

22006000

[SchM](#)

\* = Available on request