

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [51128-1601](#)
Status: **Active**
Description: 2.50mm / 3.00mm Pitch Wire-to-Board Receptacle Housing with Fuse, 16 Circuits

Documents:

[3D Model](#) [Product Specification PS-51128-003 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Housings
Series	51128
Application	Power, Wire-to-Board
Product Name	N/A
UPC	800753574007

Physical

Circuits (maximum)	16
Color - Resin	Black
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Polyphenylene Ether Alloy
Net Weight	2000.000/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm, 3.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Electrical

Current - Maximum per Contact	10A
-------------------------------	-----

Material Info

Reference - Drawing Numbers

Product Specification	PS-51128-003, RPS-51128-001, RPS-51128-002, RPS-51128-003
Sales Drawing	SD-51128-**01

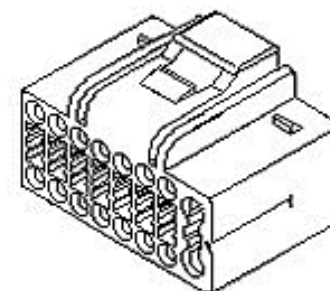


image - Reference only

Series

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

51128Series

Mates With

53526-1611 , 53526-1619

Use With

50350-9001 , 50535-9001