

## Classic ECO Ball

Classic ECO Ball 28W E14 240V Sleeve

0023485



### Range features

- 1:1 replacement of Incandescent Ball lamp
- More efficient - more savings
- Excellent colour rendering (CRI = 100)
- Instant illumination
- Sparkling light output
- Less heat generation than incandescent lamp
- Less CO2 emissions
- Identical shape as standard incandescent lamp
- Commercial and domestic application
- 100% dimmable
- Average rated life 2000 hrs - up to two times more average life compared to incandescent lamps



### PRODUCT OVERVIEW

Light colour	828 Homelight
Technology	Halogen
Ordering number	0023485
Average life (Rated) (h)	2000
Energy class	D
Lamp shape	Ball
Lamp finish	Clear
Dimmable	Yes
Cap/Base	E14
Type	Ball ECO
EAN code	5410288234854
CRI (Ra)	100
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	370
Watt (Nominal) (W)	28
Equivalent watt (W)	37
Voltage (V)	240

# Classic ECO Ball

Classic ECO Ball 28W E14 240V Sleeve

**0023485**

## DATA TABLE

### General data

<b>Ordering number</b>	0023485
<b>Technology</b>	Halogen
<b>Average life (Nominal) (h)</b>	2000
<b>Average life (Rated) (h)</b>	2000
<b>Energy saving lamp</b>	No
<b>Energy class</b>	D
<b>Lamp shape</b>	Ball
<b>Lamp finish</b>	Clear
<b>Dimmable</b>	Yes
<b>Cap/Base</b>	E14
<b>Type</b>	Ball ECO
<b>EAN code</b>	5410288234854
<b>E-number SE</b>	8355576
<b>E-number FI</b>	4740154
<b>Long description</b>	1:1 replacement of Incandescent Ball lamp. More efficient - more savings. Excellent colour rendering (CRI = 100). Instant illumination. Sparkling light output. Less heat generation than incandescent lamp. Less CO2 emissions. Identical shape as standard incandescent lamp. Commercial and domestic application. 100% dimmable. Average rated life 2000 hrs - up to two times more average life compared to incandescent lamps
<b>Product name</b>	Classic ECO Ball 28W E14 240V Sleeve
<b>Lamp mercury content (mg)</b>	0
<b>Starting time (max) (s)</b>	0.01
<b>Warm-up time to 60% of full light (max) (s)</b>	Instant full light
<b>Control gear required</b>	No
<b>Fixture rating</b>	Open
<b>IEC Reference</b>	IEC 60357
<b>IEC Reference 2</b>	IEC 60432-2
<b>Intended purpose</b>	General lighting
<b>No. of switching cycles before premature failure (min)</b>	> 8000
<b>Special purpose lamp</b>	No
<b>Transformer required</b>	No
<b>Sales pack quantity</b>	10
<b>Optimal operating condition (°C)</b>	25

## Classic ECO Ball

Classic ECO Ball 28W E14 240V Sleeve

**0023485**

### Optical data

Light colour	828 Homelight
CRI (Ra)	100
Suitable for accent lighting	No
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	370
Lumen maintenance at end of nominal life (%)	80
Luminous flux (Nominal) (lm)	370

### Electrical data

kWh per 1000 hours burning time	28
Watt (Rated) (W)	28
Watt (Nominal) (W)	28
Equivalent watt (W)	37
Voltage (V)	240
Lamp power factor	1

### Physical data


Lamp Length (mm) - C/L	83
Lamp Diameter (mm) - D	46
Packaging outer width (cm)	25
Packaging outer length (cm)	48.5
Packaging outer height (cm)	17.5
Packaging single width (cm)	4.55
Packaging single length (cm)	4.55
Packaging single height (cm)	7.6

## Classic ECO Ball

Classic ECO Ball 28W E14 240V Sleeve

0023485

### TECHNICAL DRAWINGS

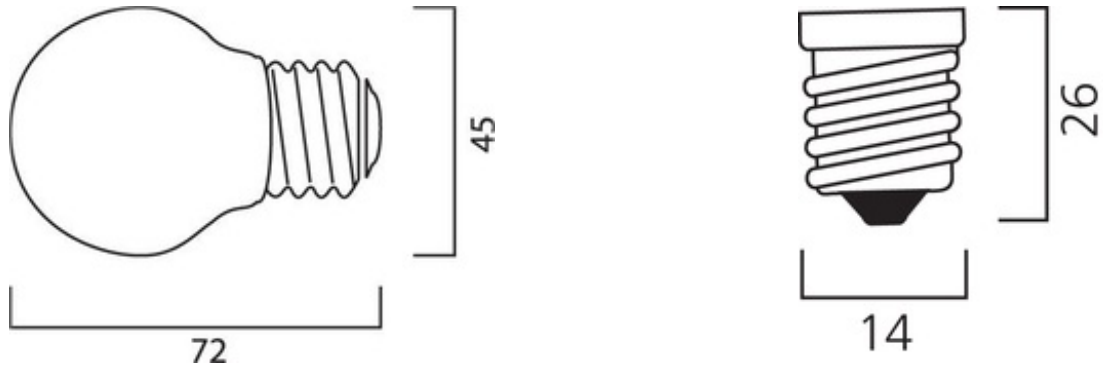

### ENERGY LABEL

