



8314

SIDE CUTTER Swedish pattern


- ✓ Acc. to DIN ISO 5749
- ✓ With slender head - ideal for confined spaces
- ✓ Induction-hardened precision cutting edges, hardness 63 - 65 HRC
- ✓ For medium-hard wire, 1.6 mm
- ✓ GEDORE special hardened and tempered steel, drop-forged, oil-hardened and annealed
- ✓ JC = chrome-plated, 2-component handles
- ✓ TL = black, with blue dipped handle protectors



JC



TL

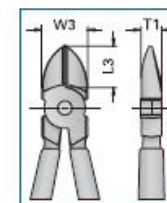

Code	No.	L	L ₃	W ₃	T ₁	Ø	W ₃	L ₃	£
6742300	8314-125 JC	125	16.0	17.0	8.5	1,6	146	5	
6740870	8314-125 TL	125	16.0	17.0	8.5	1,6	107	5	
6742730	8314-140 JC	140	18.5	18.5	9.5	1,6	176	5	
6740950	8314-140 TL	140	18.5	18.5	9.5	1,6	129	5	
6743380	8314-160 JC	160	19.0	22.0	10.0	1,6	230	5	
6741090	8314-160 TL	160	19.0	22.0	10.0	1,6	173	5	