


## Covering hood - HC-RBO 12-FE - 3247984


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

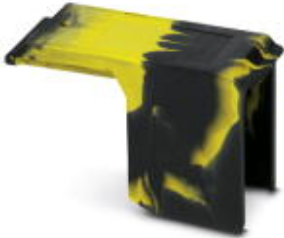

Covering hood, Connection method: Bolt connection, Width: 49 mm, Height: 33 mm, Color: black/yellow



### Key commercial data

Packing unit	6 pc
Minimum order quantity	6 pc
GTIN	 4 046356 724449
Weight per Piece (excluding packing)	39.61 g
Custom tariff number	85389099
Country of origin	China

### Technical data

#### General

Color	black/yellow
Inflammability class according to UL 94	V0

#### Dimensions

Width	49 mm
Length	164 mm
Height	33 mm
Height NS 35/7,5	33 mm
Height NS 35/15	40.5 mm

#### Connection data

Connection method	Bolt connection
-------------------	-----------------

### Classifications

#### eCl@ss

eCl@ss 4.0	27141111
------------	----------

## Covering hood - HC-RBO 12-FE - 3247984

### Classifications

#### eCl@ss

eCl@ss 4.1	27141111
eCl@ss 5.0	27141140
eCl@ss 5.1	27141140
eCl@ss 6.0	27141140
eCl@ss 7.0	27141140

#### ETIM

ETIM 3.0	EC000489
ETIM 4.0	EC002498
ETIM 5.0	EC002498

#### UNSPSC

UNSPSC 6.01	30211827
UNSPSC 7.0901	39121424
UNSPSC 11	39121424
UNSPSC 12.01	39121424
UNSPSC 13.2	39121424