

**Z-series
ZTR 2.5-2**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

**Spring connection with tension clamp Technology**

Tension clamp technology is a universal contact system for all common conductor connection types. Its fantastic level of flexibility makes the tension clamp a profitable alternative connection.

General ordering data

Type	ZTR 2.5-2
Order No.	1779010000
Version	Test-disconnect terminal, Tension clamp connection, 2.5 mm ² , 400 V, 10 A, Pivoting, Dark Beige
GTIN (EAN)	4032248184552
Qty.	100 pc(s).

Z-series
ZTR 2.5-2
Weidmüller Interface GmbH & Co. KG

 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Technical data
Dimensions and weights

Width	5.1 mm	Width (inches)	0.201 inch
Height	50.5 mm	Height (inches)	1.988 inch
Depth	43.5 mm	Depth (inches)	1.713 inch
Depth including DIN rail	44 mm	Net weight	6.6 g

Temperatures

Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C
----------------------------------	--------	----------------------------------	--------

Material data

Material	Wemid	Colour	Dark Beige
UL 94 flammability rating	V-0		

System specifications

Version	Tension-clamp connection, Disconnection element, for plug-in cross-connector, One end without connector	End cover plate required	Yes
Number of potentials	1	Number of levels	1
No. of clamping points per level	2	Number of potentials per tier	1
Levels cross-connected internally	No	PE connection	No
Mounting rail	TS 35	N-function	No
PE function	No	PEN function	No

Additional technical data

Explosion-tested version	No	Installation advice	Direct mounting
Open sides	right	Type of mounting	Snap-on

CSA rating data

Certificate No. (CSA)	200039-1152892	Current size B (CSA)	10 A
Current size C (CSA)	10 A	Current size D (CSA)	10 A
Voltage size B (CSA)	300 V	Voltage size C (CSA)	300 V
Voltage size D (CSA)	300 V	Wire cross section max. (CSA)	12 AWG
Wire cross section min. (CSA)	26 AWG		

Conductors for clamping (additional connection)

Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max.	1.5 mm ²
---	---------------------

**Z-series
ZTR 2.5-2**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Technical data
Conductors for clamping (rated connection)

Blade size	0.6 x 3.5 mm	Clamping range, rated connection, max.	2.5 mm ²
Clamping range, rated connection, min.	0.13 mm ²	Connection direction	Inclined / angled
Cross-section for connected conductor, finely stranded with wire-end ferrules and plastic collars DIN 46228/4, rated connection, min.	0.5 mm ²	Gauge to IEC 60947-1	
Number of connections	2		A2
Type of connection	Tension clamp connection	Stripping length	10 mm
Wire connection cross section AWG, min.	AWG 26	Wire connection cross section AWG, max.	AWG 12
Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, rated connection, min.	0.5 mm ²	Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, rated connection, max.	1.5 mm ²
Wire connection cross section, solid core max. rated connection	2.5 mm ²	Wire connection cross section, finely stranded, max.	2.5 mm ²
Wire connection cross-section, finely stranded with wire-end ferrules and plastic collars DIN 46228/4, rated connection, max.	1.5 mm ²	Wire connection cross section, solid core, min. rated connection	0.5 mm ²
		Wire connection cross-section, finely stranded, min.	0.5 mm ²

Disconnect terminals

Cross-disconnect	without	Integral test socket	No
Slitting	Pivoting		

Rating data

Rated cross-section	2.5 mm ²	Rated voltage	400 V
Rated current	10 A	Current at maximum wires	21 A
Standards	IEC 60947-7-1	Volume resistance according to IEC 60947-7-x	1.33 mΩ
Rated impulse withstand voltage	6 kV	Pollution severity	3

UL rating data

Certificate No. (UR)	E60693	Conductor size Factory wiring max. (UR)	12 AWG
Conductor size Factory wiring min. (UR)	26 AWG	Conductor size Field wiring max. (UR)	12 AWG
Conductor size Field wiring min. (UR)	26 AWG	Current size D (UR)	10 A
Voltage size D (UR)	300 V		

Classifications

ETIM 3.0	EC000902	ETIM 4.0	EC000902
ETIM 5.0	EC000902	ETIM 6.0	EC000902
UNSPSC	30-21-18-11	eClass 5.1	27-14-11-26
eClass 6.2	27-14-11-26	eClass 7.1	27-14-11-26
eClass 8.1	27-14-11-26	eClass 9.0	27-14-11-26
eClass 9.1	27-14-11-26		

Product information

Descriptive text technical data	2.5 mm ² flexible wires with wire-end ferrules are crimped with the Weidmüller PZ 6/5 crimping tool.
Descriptive text accessories	If the disconnect lever is replaced by the SIHA 2, a fused terminal is created.

Z-series ZTR 2.5-2

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Technical data

Approvals

Approvals



ROHS

Conform

Downloads

 
Engineering data [EPLAN, WSCAD, Zuken E3.S](#)

Declaration of Conformity [DE_PT1142_20160418_1497_ISSUE01.pdf](#)

Z-series ZTR 2.5-2

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Drawings



**Z-series
ZTR 2.5-2**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Accessories
End bracket

Klippon® Connect with clamping yoke Technology

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
EW 35 GR 7032	0383530000	Accessories, End bracket	4008190027322 50 pc(s).	
EW 35	0383560000	Accessories, End bracket	4008190181314 50 pc(s).	
EW 35/ SCHA/M3	0258660000	Accessories, End bracket	4008190033477 20 pc(s).	

Tools


Tools for removing the sheathing of uncut power cables and outgoing feeders, plus screwdrivers for installing FieldPower components.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
SDS 0.6X3.5X100	9008330000	Screwdriver, Blade width (B): 3.5 mm, Blade length: 100 mm, Blade thickness (A): 0.6 mm	4032248056286 1 pc(s).	

Z-series ZTR 2.5-2

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Accessories

Blank



ZS markers - in proven MultiCard-format - have been developed specifically for the Z-series. They have a large printing area. The hinged mechanism even allows access to cross-connectors without dismantling. Quick installation is guaranteed by the fact that the single tags are clipped on in strips. The single tags are easy to separate.

- Hinged marker area
- Can be fitted in strips or individually
- Markers in proven MultiCard format

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ZS 10/5 MC	1610000000	ZS, Terminal marker, 10 x 5	4008190263171	480 pc(s).
NE WS		mm, Pitch in mm (P): 5.00 Weidmueller, Allen-Bradley, White		

STR transparent strips



The various terminal markers from Weidmüller enable users to solve virtually every labelling task on all types of lines. Whether several lines of labelling, ready-to-use markers with standard printing, or individual labelling, whether white or coloured markers or common designations at the clamping points, the comprehensive range of products represent the easy, quick and clear answer to every marking task.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
STR 7 F.SCHT	0515300000	Terminal markers,	4008190182175	20 pc(s).
7		Protective cap, 27 x 6.3 mm, Transparent		

**Z-series
ZTR 2.5-2**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Accessories
Custom printing


The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/5 MC SDR	1609810000	Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, To customer specification	4008190456597	200 pc(s).

Test adapter

Spring connection with tension clamp Technology

Tension clamp technology is a universal contact system for all common conductor connection types. Its fantastic level of flexibility makes the tension clamp a profitable alternative connection.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ZTA 4	1688110000	Accessories, Test adapter, 11 A	4008190855666	25 pc(s).

Z-series
ZTR 2.5-2

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com


Accessories
Covers

Spring connection with tension clamp Technology

Tension clamp technology is a universal contact system for all common conductor connection types. Its fantastic level of flexibility makes the tension clamp a profitable alternative connection.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ZAD 1/4-2 GE	1764560000	Z-series, Cover	4032248066063	20 pc(s).

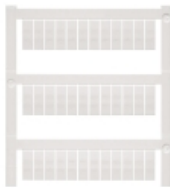Blank


WS markers are the perfect match for the W-series connectors. Thanks to their system compatibility, the WS tags can also be used with the I-series and the Z-series. The large marking surfaces do not only permit long character strings but also multi-line text. WS markers are ideal for labels with long, customised character strings. Thanks to the proven MultiCard format, printing with laser printer, PrintJet ADVANCED, plotter or MC-Mobilo is possible.

- Can be fitted in strips or individually
- Markers in proven MultiCard format

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WS 14/5 MC	1768090000	WS, Terminal marker, 14 x	4032248106271	480 pc(s).
NE WS		5 mm, Pitch in mm (P): 5.00		
		Weidmueller, White		

End brackets

Spring connection with tension clamp Technology

Tension clamp technology is a universal contact system for all common conductor connection types. Its fantastic level of flexibility makes the tension clamp a profitable alternative connection.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ZEW 35	9540000000	Z-series, End bracket	4008190956264	20 pc(s).

Z-series ZTR 2.5-2


Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmuller.com

Accessories

ZEW 35/2 [8630740000](#)

Z-series, End bracket 4032248348916 20 pc(s).

ZGB pivotable group tag holder

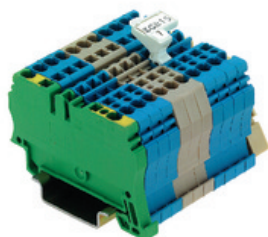

The ZGB 15 is a hinged group tag carrier. The tag carrier can hold the dekafix 5, WS 12/5 terminal markers or the inlay tag ESO 15.

The ZGB 30 is a hinged group tag carrier. The tag carrier can hold the dekafix 5, WS 12/5 terminal markers or the inlay tag ESO 7.

Inlay tags and protective strips can be found under "Accessories".

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ZGB 30	1611930000	Terminal markers, Terminal marker, 32 x 7 mm, Pitch in mm (P): 5.00 White	4008190002251	20 pc(s).
ZGB 15	1636530000	Terminal markers, Terminal marker, 15 x 7 mm, Pitch in mm (P): 5.00 White	4008190297053	20 pc(s).
ZGB 30/3.5	1778290000	Terminal markers, Terminal marker, 32 x 7 mm, Pitch in mm (P): 3.50 White	4032248161065	20 pc(s).

End plates



Spring connection with tension clamp Technology

Tension clamp technology is a universal contact system for all common conductor connection types. Its fantastic level of flexibility makes the tension clamp a profitable alternative connection.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ZAP/TW7 OR	1706130000	Z-series, End plate, Separation plate	4008190915476	50 pc(s).
ZAP/TW7 BL	1706120000	Z-series, End plate, Separation plate	4008190915469	50 pc(s).
ZAP/TW7	1706110000	Z-series, End plate, Separation plate	4008190915452	50 pc(s).

**Z-series
ZTR 2.5-2**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Accessories
ZQV 2.5

Spring connection with tension clamp Technology

Tension clamp technology is a universal contact system for all common conductor connection types. Its fantastic level of flexibility makes the tension clamp a profitable alternative connection.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ZQV 2.5/7	1608910000	Accessories, Cross-connector, 24 A	4008190159665	20 pc(s).
ZQV 2.5/9	1608930000	Accessories, Cross-connector, 24 A	4008190117009	20 pc(s).
ZQV 2.5/5	1608890000	Accessories, Cross-connector, 24 A	4008190065713	20 pc(s).
ZQV 2.5/6	1608900000	Accessories, Cross-connector, 24 A	4008190149840	20 pc(s).
ZQV 2.5/8	1608920000	Accessories, Cross-connector, 24 A	4008190061531	20 pc(s).
ZQV 2.5/4	1608880000	Accessories, Cross-connector, 24 A	4008190082208	60 pc(s).
ZQV 2.5/50	1697540000	Accessories, Cross-connector, 24 A	4008190883256	10 pc(s).
ZQV 2.5/10	1608940000	Accessories, Cross-connector, 24 A	4008190099060	20 pc(s).
ZQV 2.5/20	1908960000	Z-series, Cross-connector, For the terminals, No. of poles: 20	4032248535293	20 pc(s).
ZQV 2.5/3	1608870000	Accessories, Cross-connector, 24 A	4008190061630	60 pc(s).
ZQV 2.5/2	1608860000	Accessories, Cross-connector, 24 A	4008190123680	60 pc(s).

Reduction Sleeves

Spring connection with tension clamp Technology

Tension clamp technology is a universal contact system for all common conductor connection types. Its fantastic level of flexibility makes the tension clamp a profitable alternative connection.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ZRH 1.5H/1	1678810000	Z-series, Reducing sleeve	4008190487324	1,000 pc(s).

Creation date March 9, 2017 10:14:38 AM CET

Z-series ZTR 2.5-2

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Accessories

ZRH 1.5H/2 [1678800000](#)

Z-series, Reducing sleeve 4008190487317 1,000 pc(s).

ESO insert tags



The various terminal markers from Weidmüller enable users to solve virtually every labelling task on all types of lines. Whether several lines of labelling, ready-to-use markers with standard printing, or individual labelling, whether white or coloured markers or common designations at the clamping points, the comprehensive range of products represent the easy, quick and clear answer to every marking task.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
ESO 5 DIN A4 GE	1631350000	Terminal markers, Insert markers, 40 x 16.5 mm, Yellow	4008190206208	10 pc(s).
ESO 7 DIN A4 GE	1634780000	Terminal markers, Insert markers, 27 x 6.3 mm, Yellow	4008190273361	10 pc(s).
Discontinued	2014-09-30T00:00:00+02:00	ESO 14/6 DIN A4-BOGEN	1607740000	Terminal markers, 4008190206130 Insert markers, 34 x 4 mm, White 10 pc(s).
ESO 5 S DIN A4 WS	1631920000	Terminal markers, Insert markers, 40 x 7 mm, White	4008190206673	10 pc(s).
ESO 7 DIN A4 WS	1607720000	Terminal markers, Insert markers, 27 x 6.3 mm, White	4008190206116	10 pc(s).
ESO 15 DIN A4 WS	1636510000	Terminal markers, Insert markers, 15 x 6 mm, White	4008190425494	10 pc(s).
ESO 7 P DIN A4 WS	1670390000	Terminal markers, Insert markers, 27 x 6.3 mm, White	4008190430719	10 pc(s).
ESO 7 P DIN A4 GE	1670400000	Terminal markers, Insert markers, 27 x 6.3 mm, Yellow	4008190430726	10 pc(s).
ESO 5 DIN A4 WS	1607710000	Terminal markers, Insert markers, 40 x 16.5 mm, White	4008190206109	10 pc(s).
ESO 5 P DIN A4 GE	1670380000	Terminal markers, Insert markers, 40 x 16.5 mm, Yellow	4008190430702	10 pc(s).
ESO 5 P DIN A4 WS	1670370000	Terminal markers, Insert markers, 40 x 16.5 mm, White	4008190430696	10 pc(s).
ESO/SCHS1 500X12,5X0,3	0139000000	Terminal markers, Insert markers, 500 x 12.5 mm, White	4008190047252	100 pc(s).

**Z-series
ZTR 2.5-2**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Accessories

ESO 8 DIN A4 [1607730000](#)
WS

Terminal markers, Insert 4008190206123 1 pc(s).
markers, 24.5 x 5 mm,
White

End brackets**Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WEW 35/2	1061200000	W-Series, End bracket	4008190030230	100 pc(s).
WEW 35/1	1059000000	W-Series, End bracket	4008190172282	50 pc(s).

Addresses worldwide

Let's connect.

AE United Arab Emirates
Weidmüller Middle East FZE
Warehouse Q3-79
SAIF-Zone
P.O. BOX 8591
Sharjah
Telephone number +971 65572723
Fax number +971 65572724
wme.info@weidmuller.com

AF Afghanistan
Representative Office

AF 11050 Beograd
Telephone number +381 11 2885 274
Fax number +381 11 2885 274
zoran.rabrenovic@weidmuller.com

AO Angola
Please contact
Phambili Interface
South Africa

AR Argentina
CPI SA
Bauness 2660
C1431DOF Buenos Aires
Telephone number +54 11 4523 8008
Fax number +54 11 4522 0546
info@cpi.com.ar
www.cpi.com.ar

AT Austria
Weidmüller GmbH
IZ NOE Süd, Str 2b, Obj M59,
2355 Wiener Neudorf
Telephone number +43 2236 67080
Fax number +43 2236 6708-899
office.at@weidmuller.com
www.weidmuller.com

AU Australia
Weidmüller Pty. Ltd.
PO BOX 6944
Huntingwood 2148
Huntingwood Drive 43
Huntingwood NSW 2148
Telephone number +61 2 9671 9999
Fax number +61 2 9671 9911
info@weidmuller.com.au
www.weidmuller.com.au

AZ Azerbaijan
Representative Office
Weidmüller Interface
Demirchi Tower, 4th floor
37, Khojali ave.
AZ 1025 Baku
Telephone number +994 12 488 80 36
Fax number +994 12 488 80 37
aliyar.hashimli@weidmuller.com

BA Bosnia and Herzegovina
Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
Serbia

or
BH ES Elektrosistem d.o.o.
Palih boraca 104
78000 Banja Luka
Telephone number +387 51 420 340
Fax number
elsist@inecco.net
www.elektrosistem.ba
BIG electric d.o.o
Mladena Stojanovića 117A
78000 Banja Luka
Telephone number +387 51926277
Fax number +387 51926277
bigelectric@blic.net
www.bigelectric.ba

BE Belgium
Weidmüller Benelux B. V.
Mechelsesteenweg 519 bus
6 en 7
1930 Nossegem
Telephone number +32 2 752 40 70
Fax number +32 2 751 36 06
info@weidmuller.be
www.weidmuller.be

BG Bulgaria
Weid-Bul EOOD
Bul. „Kliment Ohridski“ 13
1756 Sofia
Telephone number +359 2 963 2560
Fax number +359 2 963 1098
sofia@weidbul.com
www.weidbul.com

BH Bahrain
Khayber Trading Company
P.O Box 1976
Manama
Telephone number +973 720747
Fax number +973 720331
khayber@batelco.com.bh

BR Brazil
Weidmüller Conexel do Brasil
Conexões Elétricas Ltda.
Av. Presidente Juscelino, 642
- Piraporinha
Diadema, São Paulo
09950-370
Telephone number +55 (11) 4366-9600
Fax number +55 (11) 4362-1677
vendas@weidmuller.com.br
www.weidmuller.com.br

BW Botswana
Please contact
Phambili Interface
South Africa

BY Belarus
TECHNIKON Ltd.
Nezavisimosti pr. 177-9
220125 Minsk
Telephone number +375 17 393-11-77
Fax number +375 17 3930080
wm@technikon.by

CA Canada
W Interconnections Canada Inc.
10 Spy Court
Markham Ontario L3R 5H6
Telephone number +1 (905) 475-1507 Ext. 9836
Fax number +1 (905) 475-2798
support@weidmuller.ca
www.weidmuller.ca

CG Congo
Please contact
Phambili Interface
South Africa

CH Switzerland
Weidmüller Schweiz AG
Rundbuckstraße 2
8212 Neuhausen am
Rheinfall SH
Telephone number +41 52 674 07 07
Fax number +41 52 674 07 08
info@weidmuller.ch
www.weidmuller.ch

CL Chile
CPI CHILE LTDA
Av. Presidente Frei Montalva
6001, 47 complejo el cortijo
Santiago - Conchalí
Telephone number +562 963 8440
Fax number +562 963 8440
cpi@cpichile.cl
www.cpicchile.cl

CN China
Weidmüller Interface
(Shanghai) Co. Ltd.
100 Yutong Road
25 F. BM Intercontinental
Business Center
200070 Shanghai
Telephone number +86 21-22195008
Fax number +86 21-22195009
customer.hotline@weidmuller.com.cn
www.weidmuller.com.cn

CO Colombia
Automatización Avanzada S. A.
Carrera 97 No., 24 c - 23
Bodega 4
110911 Bogotá-D.C.
Telephone number +57 (1) 547-8510
Fax number +57 (1) 422-3044
comercial@automatizacionavanzada.com
www.automatizacionavanzada.com

CR Costa Rica
ELVATRON S. A.
la Uruca 400 Norte Banco
Costa Rica
San Jose Costa Rica
Telephone number +506 2961-060
Fax number +506 5200-609
dirk.haase@elvatron.com
www.elvatron.com

CZ Czech Republic
Weidmüller s.r.o.
Lomnického 5/1705
140 00 Praha 4
Telephone number +420 244 001 400
Fax number +420 244 001 499
office@weidmuller.cz
www.weidmuller.cz

DE Germany
Weidmüller GmbH & Co. KG
Ohmstraße 9
32758 Detmold
Postfach 30 54
32720 Detmold
Telephone number +49 5231 1428-0
Fax number +49 5231 14-292083
weidmuller@weidmuller.de
www.weidmuller.de

DK Denmark
Weidmüller Danmark
Vallensbækvej 18A
2605 Brøndby
Telephone number +45 27747800
kundeservice@weidmuller.dk
www.weidmuller.dk

DZ Algeria
SARL INTER ELECTRIC
1a Angles des Rues Okba Ibn
Nafaa et Hassi Beida
2300 Annaba
Telephone number
Fax number
contact@inter-electric.com

EC Ecuador
Elsystec S. A., Electricidad
Sistemas y Tecnología
Vasco de Contreras N35-251
y Mañosca
Quito - Pichincha
Telephone number +593 22456510
Fax number +593 22456755
Elsystec@uio.satnet.net

EE Estonia
Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
Latvia

or
SLO Eesti AS

11415 Tallinn
Telephone number +372 6 272 200
Fax number
info@slo.ee

SLO Eesti AS

12618 Tallinn
Telephone number +372 622 9119
Fax number
elit@elit.ee

Soots Interface OÜ
Pärnu mnt 142
11317 Tallinn
Telephone number +372 609 6933
Fax number
info@sootsinterface.ee
www.sootsinterface.ee

EG Egypt
Standard Electric (OMEGA)
1, Abdelhamid Badawy Street
Heliopolis
Cairo
Telephone number +202 21805111
Fax number +202 21805600
stdelec@rite.com

ES Spain
Weidmüller, S. A.
Narcis Monturiol 11-13, Pol.
Ind. Sudoeste
8960 Sant Just
Desvern - Barcelona
Telephone number +34 934 803 386
Fax number +34 933 718 055
weidmuller@weidmuller.es
www.weidmuller.es

FI Finland
Weidmüller Suomi,
Weidmüller Aktiebolagetin
sivuliike
Koy Plaza Vivace
Äyritie 8C
FI 1510 Vantaa
Telephone number +358 20 7351300
Fax number +358 800 114 667
asiakaspalvelu@weidmuller.fi
www.weidmuller.fi

FR France
Weidmüller E. U. R. L.
2 Boulevard de l'Oise
CS 31100 CERGY
95095 CERGY PONTOISE
Cedex
Telephone number +33 1 34 24 55 00
Fax number +33 1 34 24 55 01
mail@weidmuller.fr

GB Great Britain
Weidmüller Ltd.
Klippon House
Centurion Court Office Park,
Meridian East, Meridian
Business Park
Leicester
LE19 1TP
Telephone number +44 116 282 3470
Fax number +44 116 289 3582
marketing@weidmuller.co.uk
www.weidmuller.co.uk

GE Georgia
Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.

GH Ghana
Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
South Africa.

GR Greece
G.A. Solutions
Ippokratous 11 Metamorfosi
144 52 Athens
Telephone number +30 210 2823233
Fax number +30 210 2823233
info@weidmuller.gr
www.weidmuller.gr

GT Guatemala
Prestelectro, Prestegard
Electro, S.A.
Avenida Petapa 44-22,
Zona 12
Guatemala City
Telephone number +502 2442-3346
Fax number +502 2476-8945
ventas@prestelectro.com

HK Hong Kong
Weidmüller (Hong Kong)
Limited Co. Ltd.
Unit 1617, Metropolis Tower
No. 10 Metropolis Drive,
Hung Hom, Kowloon
Telephone number +852 3154 8088
Fax number +852 31548099
Info-hk@weidmuller.com.hk

HR Croatia
ElektroPARTNER d.o.o.
Slavonska avenija 24/6
HR-10000 Zagreb
Telephone number +385 (1) 6184 793
Fax number +385 (1) 6184 795
elektropartner@zg.t-com.hr
www.elektropartner.hr

HU Hungary
Weidmüller Kereskedelmi Kft.
Budapest
Gubacsi út 6.
1097
Telephone number +36 1 382 7700
Fax number +36 1 382 7701
info@weidmuller.hu
www.weidmuller.hu

ID Indonesia
PT. Nego Electrindo
Ruko Mega Grosir Cempaka
Mas Blok I No. 20 - 22
Jakarta 10640
Telephone number +62 21 42882255
Fax number +62 21 42882266
sales@negoelectrindo.co.id

IE Ireland
Please contact
Weidmüller Ltd.
Great Britain

IL Israel
A. U. Shay Ltd.
23/25, Embarr Street
49222 Petach-Tikva
P.O. Box 1 00 49
49222 Petach-Tikva
Telephone number +972 3-923-3601
Fax number +972 3-923-4601
shay@uriel-shay.com
www.uriel-shay.com
ATEKA Ltd.
4, Ha Tavor lane Industrial
area Segula
49691 Petach-Tikva
P.O. Box 4710
Petach-Tikva
Telephone number +972 73-200-1311
Fax number +972 3-924 4245
marketing@ateka.co.il
www.ateka.co.il



You can find all Weidmüller addresses and your local contact on the internet at: www.weidmuller.com/countries

Let's connect.

Sales company 

Representation abroad 

without representation abroad 

IN India Representative Office Weidmüller Electronics India Pvt. Ltd. No. 9, Union Street, Off. Infantry Road BANGALORE 560 001 Telephone number +91-80-22860028 wmi@weidmuller.in www.weidmuller.com	KW Kuwait Kana Controls General Trading & Contracting Co. W. L. L. Al Rai Industrial Area, Plot 28-30, St. 31 13016 Safat B.P. 25593 Telephone number +965 4741373 Fax number +965 4741537 info@kanacontrols.com Petroleum Services Co. W.L.L. Kuwait Trade Free Zone Area P.O. Box 4098 Safat 13041 Telephone number +96524610801/2/3 ext. 208 II Fax number +96524613754 psc-systems@petserv.net	MD Moldova Inoxpa Solutions SRL 20, Igor Vieru street MD-2075 Chisinau Moldova Telephone number +373 (22) 866665 Fax number +373 (22) 866663 atiuleanu@gmp-moldova.com www.gmp-moldova.com	NA Namibia Please contact Phambili Interface South Africa	PK Pakistan Automation Controls (Pak) Apartment No. 33 C III, Chensab Block, Allama Iqbal Town Lahore Telephone number +92 42 37809948 Fax number +92 42 37809950 nadeem@acpak.com.pk www.acpak.com.pk
IR Iran Representative Office Tamin Ehtiajat Fanni Tehran (TAF Co.) No. 36, West 4th St., Ettehad Ave. Damavand Rd. Tehran - 1658674583, Iran Telephone number +9821 77120809 info@taf-co.com http://www.taf-co.com	KZ Kazakhstan Please contact Weidmüller Group Russia	ME Montenegro Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Serbia.	NG Nigeria Please contact Weidmüller Interface GmbH & Co. KG South Africa	PL Poland Weidmüller Sp. z o.o. ul. Ogrodowa 58 00-876 Warszawa Telephone number +48 22 510 09 40 Fax number +48 22 510 09 41 biuro@weidmuller.com.pl www.weidmuller.pl
IS Iceland Samey Automation Center Lyngas 13 210 Garoabaer Telephone number +354 510 5200 Fax number +354 5 10 5201 Samey@samey.is www.samey.is	LB Lebanon Progress Engineering & Trading Enterprises Al Nahr Street Beirut 11-1111 Telephone number +961 1 444 664 Fax number +961 1 561 880 progress@inco.com.lb	MG Madagascar Please contact Phambili Interface South Africa	NL Netherlands Weidmüller Benelux B. V. Franciscusweg 221 1216 SE Hilversum P.O. Box 1505 1200 BM Hilversum Telephone number +31 35 626 12 61 Fax number +31 35 623 20 44 info@weidmuller.nl www.weidmuller.nl	PR Puerto Rico Please contact W Interconnections Inc. United States
IT Italy Weidmüller S. r.l. Via Albert Einstein 4 20092 Cinisello Balsamo Milano Telephone number +39 02 680681 Fax number +39 02 6124945 weidmuller@weidmuller.it www.weidmuller.it	LT Lithuania Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Latvia or ELEKTROS IRANGA Tinklų g. 29 a LT-5319 Panevėžys Telephone number +370 (45) 582 828 Fax number +370 (45) 582 727 info@eliranga.lt UAB „SLO Lithuania“ Vilkipėdės g. 4 LT-LT-03151 Vilnius Telephone number +370 5 215 00 70 Fax number +370 5 215 00 71 biuras@slo.lt	MK Macedonia Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Serbia or ELEKTRO - SMK dooel UL. III Makedonska brigada b.b. 1000 Skopje Telephone number +389 22460295 Fax number Elektro-smk@telekabel.net.mk	NO Norway Sivilingeniør J.F. Knudtzen AS Billingstadsletta 97 1396 Billingstad PO Box 160 1378 Nesbru Telephone number +47 66 98 33 50 Fax number +47 66 98 09 55 firmapost@jfkudtzen.no www.jfkudtzen.no	PT Portugal Weidmüller Sistemas de Interface S. A. Estrada Outeiro Polima, R. Augusto Dias da Silva, Lote B - Esc. 2 São Domingos de Rana 2785-515 Abóboda Telephone number +351 214 459 191 Fax number +351 214 455 871 weidmuller@weidmuller.pt www.weidmuller.pt
JM Jamaica Please contact W Interconnections Inc. United States	LU Luxembourg Please contact Weidmüller Benelux B. V. Netherlands	MN Mongolia Please contact our Representative Office Weidmüller Interface Azerbaijan.	NZ New Zealand Cuthbert S. Steward Ltd. 27 Te Puni Street Petone PO Box 38496 Wellington Mail Centre 5054 Telephone number (04) 568 6156 Fax number (09) 489 1752 csi@cuthbertstewart.co.nz Cuthbert S. Steward Ltd 4 Fred Thomas Drive Aon Building, Ground Floor, South Entry Takapuna PO Box 100 338 North Shore City 745 Telephone number (09) 489 1751 Fax number (04) 568 6056 csiak@cuthbertstewart.co.nz	PY Paraguay Please contact CPI SA Argentina
JO Jordan Billeh Electricals Mat. Co. PO Box 4343 Amman Telephone number +962 6 4656 987 Fax number +962 6 4649 216	LV Latvia SIA Abi4 Daugavgrivas 49 k3 Riga, LV-1007 Telephone number +371 674 70999 Fax number abi_4@tvnet.lv Representative Office Weidmüller Interface GmbH & Co. KG Udens str. 12-118 Riga, LV-1007 Telephone number +371 29254766 Fax number lgonis.rudaks@weidmuller.com www.weidmuller.com	MT Malta E. S. S., Electrical Supplies & Services Ltd. San Gwakkim Road Mriehel Telephone number +356 21255777 Fax number +356 21255999 robert.agius@ess.com.mt	OM Oman DAN INTERNATIONAL LLC. Ghala St. 111 BP 2901 Seeb Telephone number +968 5036 77 Fax number +968 5037 55 yedu@danintl.com	QA Qatar Doha Motors PO Box 145 Telephone number +974 4651441 Fax number +974 4654579 dmtctech@qatar.net.qa http://www.dohamotorsgroup.com/td.html
JP Japan Nihon Weidmüller Co. Ltd. Sphere Tower Tennoz 2-2-8 Higashi-Shinagawa, Shinagawa-ku Tokyo 140-0002 Telephone number +81 3 6711 5300 Fax number +81 3 6711 5333 info@weidmuller.co.jp www.weidmuller.co.jp	RO Romania Representative Office Weidmüller Interface GmbH & Co. KG Ionescu Crum Street, No. 1, 1st Tower, 1st Floor, Office 4 500446 Brasov - Brasov Business Park Telephone number +40 (268) 446 222 Fax number +40 (268) 446 224 claudiu.totea@weidmuller.com www.weidmuller.ro	MU Mauritius Mubelo Electrical Ltd. Office 26, Gateway building, St Jean Road Quatre Bornes Mauritius Telephone number +230 4670989 Fax number +230 4654051 richard.mubelo@orange.mu	PE Peru IMPEXINCA S.A.C. Calle Ortiz de Zevallos No. 105, Urb. San Antonio 18 Lima, Miraflores Telephone number +51 1 447 5608 info@impexinca.pe www.impexinca.pe J & W CIA. S. A. Calle 6 Mz. D Lte. 23, Urb. Ind. Grimanesa 01 Callao Telephone number +51 1 572 2539 Fax number +51 1 572 0152 contacto@jwcia.com www.jwcia.com	RS Serbia Representative Office Weidmüller Interface GmbH & Co. KG Ustanicka 189, III sprat lokal 7a 11050 Beograd Telephone number +381 112885274 Fax number +381 112885274 zoran.rabrenovic@weidmuller.com TeLa Elektrik d.o.o. Ul. Dr. Drage Ljocić 6 Beograd Telephone number +381 11 2772 415 Fax number +381 11 2772 850 office@tela.rs www.tela.rs
KE Kenya Please contact our Representative Office Weidmüller Interface GmbH & Co. KG South Africa.	MA Morocco Sofimed 137, Bd Moulay Ismail Roches Noires 20290 Casablanca Telephone number Fax number contact@sofimedmaroc.com	MX Mexico W Interconnections S. A. DE C. V. Blvd. Hermanos Serdán 698, Col. San Rafael Oriente 72029 Puebla Telephone number +52 (222) 268 6227 Fax number +52 (222) 286 6242 clientes@weidmuller.com.mx	PH Philippines Enclosure Systems Specialists Inc. 2276 Don Chino Roces Avenue Extension Room 103/105 Narra Building 1231 Makati City Telephone number +63 2 813 8580 Fax number +63 2 813 8596 sales_encsys@pltdsl.net www.enclosuresystemsph.com	
KG Kyrgyzstan Please contact our Representative Office Weidmüller Interface Azerbaijan.		MY Malaysia Connect Plus Technology Sdn Bhd No. 43, Jalan PJS 11/22, Bandar Sunway 46150 Petaling Jaya Selangor Darul Ehsan Telephone number +60 3 5633 7363 Fax number +60 3 5633 6562 paul@cptech.com.my www.cptech.com.my		
KR Korea Weidmüller Korea Co. Ltd. 9th floor 429, Teheran-ro, Gangnam-Gu Seoul 135-721 Telephone number +82 2-516-0003 Fax number +82 2-516-0090 info@weidmuller.co.kr www.weidmuller.co.kr		MZ Mozambique Please contact Phambili Interface South Africa		

Addresses worldwide

Let's connect.

- RU Russia**
Weidmüller Group
7/10 Khlebozavodskiy
Passage,
Moskau
115230
Telephone number +7 495
280 72 71
Fax number +7 495 280
72 71
Info@weidmueller.ru
www.weidmueller.ru
- SA Saudi Arabia**
Al Abdulkarim Holding Co.
P.O. Box 4
Dammam 31411
Telephone number +966 3
8337 110
Fax number +966 3
8829547
E-mail salehsk@akh.com.sa
www.weidmueller.ae

Saudi Electric Supply
Company (SESCO)
P.O. Box 32 98
Al Khobar 31952
Telephone number +966 3
8829546 Ext. 3030
Fax number
E-mail Safdar.Malik@sescogex.com
www.sesco-gex.com
- SE Sweden**
Weidmüller AB
Axel Danielssons väg 271
BOX 31025
SE-200 49 Malmö
Telephone number +46 77-
143 00 44
Fax number +46 40-37 48 60
info@weidmuller.se
www.weidmuller.se
- SG Singapore**
Weidmüller Pte. Ltd.
70 Bendemeer Road
04-03 Luzerne Building
Singapore 339940
Telephone number +65 6841
5311
Fax number +65 6841 5377
info@weidmuller.com.sg
www.weidmuller.com.sg
- SI Slovenia**
Elektrospoji d. o. o.
Stegne 27
Sl- 1000 Ljubljana
Osrednjeslovenska
Telephone number +386 1
511 3810
Fax number +386 1 511
1604
info@elektrospoji.si
www.elektrospoji.si
- SK Slovakia**
ELEKTRIS s.r.o.
Elektrárenská 1
831 04 Bratislava
Telephone number +421
2/4920 0113
Fax number +421 2/4920
0119
bratislava@elektris.sk
- SV El Salvador**
Prestegard Electro
11 Avenida Norte No. 240
Edificio Salazar No. 2
San Salvador
Telephone number +503
2271 1690
Fax number +503 2221
3851
prestegard@navegante.com.sv
- SY Syria**
Please contact
Weidmuller Middle East FZE
United Arab Emirates
- SZ Swaziland**
Please contact
Phambili Interface
South Africa
- TH Thailand**
Pisanu Engineering Co. Ltd.
Kwang Dingaeng, Khet
Dingaeng
800/2 Soi Trakulsuk, Asoke-
dindaeng Road
Dindaeng, Bangkok
10400
Telephone number +66 2
248 2896
Fax number +662 105 6301
ecsales@pisanu.co.th
www.pisanu.co.th

Representative Office
Weidmüller Pte. Ltd.
37/F, Sathorn Square Building
98 North Sathorn Road
Bangkok, Silom Bangrak
10500
Telephone number +66 2
105 6300
Fax number +66 2 642 9220
info@weidmuller.com.sg
- TJ Tajikistan**
Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.
- TM Turkmenistan**
Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.
- TN Tunisia**
Please contact
Weidmüller E. U. R. L.
France
- TR Turkey**
Weidmüller Elektronik Ticaret
Ltd. Sirketi
Kavacik Mah. Orhan Veli Kanik
Caddesi 9/1
34810 Beykoz / Istanbul
Telephone number +90 (216)
537 10 70
Fax number +90 (216) 537
10 77
info@weidmuller.com.tr
www.weidmuller.com.tr
- TW Taiwan**
Please contact
Weidmuller (Hong Kong)
Limited Co. Ltd.
Hong Kong
- TZ Tanzania**
Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
South Africa.
- UA Ukraine**
LLC WM UKRAINE
Levanevskogo str. 6
Kiev
3058
Telephone number +38 044
490 32 48
Fax number
info@wm-ua.com.ua
wm-ua.com.ua/

Representative Office
Weidmüller Interface GmbH
& Co. KG
Z, office 303
7-D, Zdolbunivska str.
Kiev, 2081
Telephone number
(mobile) +38 050 440 25 24
info.ua@weidmueller.com
- US United States**
W Interconnections Inc.
821 Southlake Boulevard
Richmond Virginia 23236
Telephone number +1 (804)
794-2877
Fax number +1 (804) 379-
2593
info@weidmuller.com
www.weidmuller.com
- UY Uruguay**
REWO Uruguay S. A.
AV. Bolivia 2001Esq
Roca fuerte
11300 Carrasco Montevideo
Telephone number +598
2604 8439
Fax number +598 2604
8439
rewo@rewouruguay.com.uy
- UZ Republic of Uzbekistan**
Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.
- VE Venezuela**
Somerinca C. A.
Corazon de Jesus - 3ra
Transversal con calle el
Carmen- Los Dos Caminos
Caracas 1070-A
Telephone number +58
2122352748
Fax number +58
2122399341
klocmoeller@cantv.net
www.somerinca.com
- VN Vietnam**
AUMI Industrial Equipment &
Automation Company Limited
E1, La Thanh Hotel
218 Doi Can Street
Lieu Giai Ward, Ba Dinh
District
Hanoi City
Telephone number +84 4
37628601
Fax number +84 4
62661391
aumi@aumi.com.vn
www.aumi.com.vn

Representative Office
Weidmüller Pte. Ltd.
Level 16 Saigon Tower
Building
29 Le Duan Street
District 1
Ho Chi Minh
Telephone number +848
3520 7717
Fax number +848 3520
7604
info@weidmuller.com.sg
- ZA South Africa**
Phambili Interface
PO Box 193
1609 Johannesburg, Edenvale
5 Bundo Road, Sebenza
1610 Johannesburg
Telephone number +27 (11)
4521930
Fax number
info@weidmuller.co.za
www.weidmuller.co.za

Representative Office
Weidmüller Interface GmbH
& Co. KG
210 Amarand
Avenue, Pegasus Building
181 Pretoria, waterkloof Glen
ext 2 -
Telephone number +27 12
003 2906
Fax number +27 (11)
4526455
Jacques.Vosloo@weidmueller.
com
www.weidmueller.com
- ZM Zambia**
Please contact
Phambili Interface
South Africa
- ZW Zimbabwe**
Please contact
Phambili Interface
South Africa