


## 25PC. 1/2"DR. SOCKET SET (S.A.E.)

**New**

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09921	375	180	45	4	17.8


### DESCRIPTION:

- 15 - 6Pt. S.A.E. Sockets  
5/16", 3/8", 7/16", 1/2", 9/16", 5/8", 11/16", 3/4", 13/16", 7/8", 15/16", 1", 1-1/16", 1-1/8", 1-1/4"
- 5 - 6Pt. S.A.E. Deep Sockets 1/2", 9/16", 5/8", 3/4", 13/16"
- 5 - Accessories  
Quick-Release Ratchet  
Wobble Extension Bar 10"  
Locking Extension Bar 5"  
Universal Joint  
3 Way Adapter 3/8"Fx1/2"




## 27PC. COMBINATION WRENCH AND HEX KEY SET

**New**

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09922	375	180	45	4	10.0


### DESCRIPTION:

- 9 - Mirror Finish Combination Wrenches 1/4", 5/16", 3/8", 7/16", 1/2", 9/16", 5/8", 11/16", 3/4"
- 9 - Extra Long Ball Point Hex Key Set 1.5, 2.0, 2.5, 3, 4, 5, 6, 8, 10mm
- 9 - L-Type Torx® Key TT10, TT15, TT20, TT25, TT27, TT30, TT40, TT45, TT50

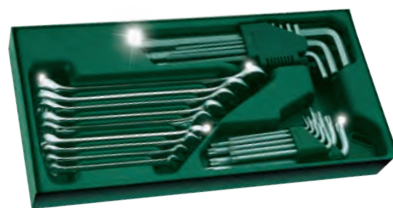

## 14PC. RATCHETING COMBINATION WRENCH SET (S.A.E.)

**New**

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09923	375	180	45	4	8.5


### DESCRIPTION:

- 10 - S.A.E. Ratcheting Wrenches 5/16", 3/8", 7/16", 1/2", 9/16", 5/8", 11/16", 3/4", 13/16", 7/8"
- 1 - 1/4"Dr.x10mm Quick-Release Adapter
- 1 - 3/8"Dr.x13mm Quick-Release Adapter
- 1 - 1/2"Dr.x19mm Quick-Release Adapter
- 1 - 1/4"Dr. HSC 10mm




## 21PC. 1/2"DR. SOCKET SET (S.A.E.)

**New**

PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
09924	375	180	45	4	15.0


### DESCRIPTION:

- 15 - 6Pt. S.A.E. Sockets  
5/16", 3/8", 7/16", 1/2", 9/16", 5/8", 11/16", 3/4", 13/16", 7/8", 15/16", 1", 1-1/16", 1-1/8", 1-1/4"
- 5 - 6Pt. S.A.E. Deep Sockets 1/2", 9/16", 5/8", 3/4", 13/16"
- 1 - Quick-Release Ratchet

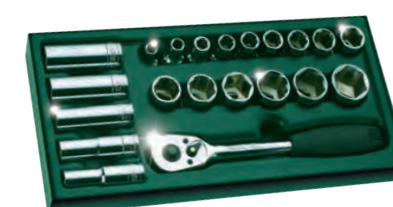

## ACCESSORY BOX


PART NO.	LENGTH MM	WIDTH MM	HEIGHT MM		G.W. (kg)
95114	180	25	45	25	1.8

-  Nature of this product is subject to wear and tear upon usage. Not covered under Lifetime Warranty.



## 15PC. TOOL SET

**New**

PART NO.	CONTENT		G.W.(kg)
06008	15PC.	4	13.1

### DESCRIPTION:

- 3 - Screwdrivers  
Flat 5mm x 100mm  
Phillips #1 x 100mm  
Detection (Pocket Model) 145mm
- 12 - Accessories  
Adjustable Wrench / Dipping Grip 8"  
Long Nose Pliers 6"  
Linesman Pliers 6"  
Insulated Tape  
Fine Point Tweezer  
Tape Measure 3m x13mm  
Utility Knife  
Scissors  
Alum Flashlight 5#  
Mini Hacksaw  
Claw Hammer W / Wood Handle 8 Oz  
Plastic Box



## 16PC. MOTOR CYCLE REPAIR TOOL SET

**New**

PART NO.	CONTENT		G.W.(kg)
09512	16PC.	4	13.3

### DESCRIPTION:

- 9 - Combination Wrenches  
11, 12, 13, 14, 15, 16, 17, 18, 19mm
- 3 - Double Box End Wrenches  
8x10, 14x17, 19x21mm
- 4 - Screwdrivers  
Phillips #2x38mm, #2x150mm  
Flat 6x38mm, 6x150mm



## 53PC. PROFESSIONAL ELECTRONIC TOOL SET

**New**



PART NO.	CONTENT		G.W.(kg)
09535	25PC.	2	9.8


### DESCRIPTION:

- 11 - 1/4"Dr. 6pt. Sockets 4, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13mm
- 15 - 1/4"Dr. Bit Sockets Slotted 4, 5.5, 6.5mm Phillips #1, #2, #3 Torx® T10, T15, T20 Hex 2, 2.5, 3, 4, 5, 6mm
- 4 - Screwdrivers Phillips #1x75mm, #2x100mm Slotted 5x75mm, 6x100mm
- 6 - Precision Screwdrivers Phillips #0x75mm, #0x100mm, #1x150mm Slotted 2x75mm, 3x100mm, 4x150mm
- 17 - Accessories  
1/4"Dr. Bit Adapter 25mm  
Bit Screwdriver With Magnet  
Detecting Screwdriver  
Long Nose Pliers 6"  
Diagonal Pliers 6"  
Electrician's Knife  
Long Life Soldering Iron 30w  
Mini Stand For Soldering Iron  
Anti-static Brush  
Digital Multi-meter  
Solder Absorber  
Insulated Tape  
Adjustable Wrench / dipping Grip 6"  
Solder Wire 1.0mm / 17g  
Aluminum Flashlights  
Self Adjusting Cutter Stripper 6-1/2"  
Measure Tape 3mx13mm





## DETECTION SCREWDRIVER (POCKET MODEL)


PART NO.	SIZE MM			G.W. (kg)
62501	145	24	252	4.7
62502	185	24	180	5.0

-  Nature of this product is subject to wear and tear upon usage. Not covered under Lifetime Warranty.



## AUTO VOLTAGE TESTER

PART NO.	SIZE			G.W. (kg)
62503	6V-12V-24V	10	40	5.4

-  Nature of this product is subject to wear and tear upon usage. Not covered under Lifetime Warranty.

