



Potentiometer

Potentiometers

Operator: Potentiometer

Description	Catalog number	Weight oz.
Complete Potentiometers		
Black knob with integrated position indication and marking in white		
With resistor 5 kohm		
Black plastic bezel	MT-105B	1.4
Chrome metal bezel	MT-305B	1.7
With resistor 10 kohm		
Black plastic bezel	MT-110B	1.4
Chrome metal bezel	MT-310B	1.7
With resistor 50 kohm		
Black plastic bezel	MT-150B	1.4
Chrome metal bezel	MT-350B	1.7

Knob without Resistor




Black knob with integrated position indication and marking in white.
For shaft diameter 6 -6.35 mm.
Min. shaft length 20 mm.

Black plastic bezel	KT-100B	1.2
Chrome metal bezel	KT-300B	1.5

Legend plates aluminum

Symbol: see fig.	(29.6 x 44.5 mm)	SK 615 562-87	0.071
Scale: 0-10	(48.5 x 44.5 mm)	SK 615 562-88	0.071
Scale: 0-50	(48.5 x 44.5 mm)	1SFA611830R1252	0.071

Legend plates

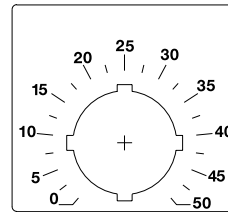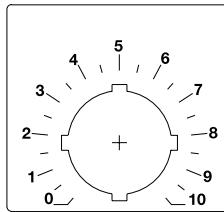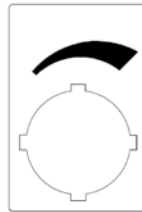

Buzzers



Buzzer

Operator: Buzzer

Description	Catalog number		Weight oz.
Buzzers			
Black. Frequency: Approx. 2400 Hz. Loudness: Min 80 dB (A)/10 cm Rated Current: < 8 mA. Service Life:>5000 h Suitable for both 50 and 60 Hz networks			
Supply voltage	Tone	Catalog number	
24 V AC/DC	Continuous	KB1-4010	0.020
115 V AC/DC	Continuous	KB1-4030	0.020
230 V AC	Continuous	KB1-4040	0.020
24 V AC/DC	Pulsating	KB1-4110	0.020
115 V AC/DC	Pulsating	KB1-4130	0.020
230 V AC	Pulsating	KB1-4140	0.020

Resistor data

Element Catalog No.	Cermet
Power rating	2 W
Mechanical angle	280°
Terminals	Screw terminated
Insulation voltage	900 V
Operating temperature	-1 – +70 °C