



Wire Management

Type DNG

Description: Similar to BA6 but fingers are formed with wire-retaining slots.

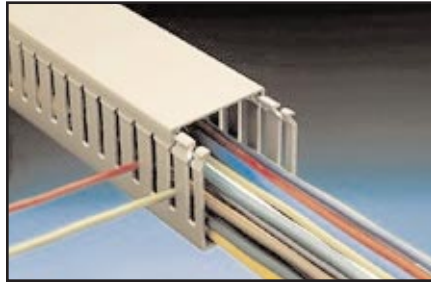


Sidewalls are prescored to permit enlarging slot for load-offs without the need for tools or cutting.

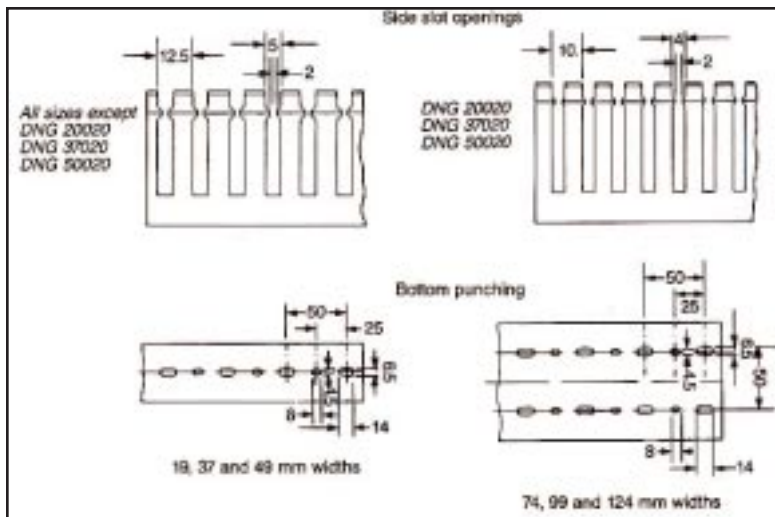

Catalog Number	Dimensions (W x H) Nominal Inches	Max. No. of 18 AWG at 50% Area Fill	Std. Pkg. Ft.
DNG 20020-(G or PW)	0.75 x 0.75	23	210
DNG 37020-(G or PW)	0.75 x 1.50	43	105
DNG 50020-(G or PW)	0.75 x 2.00	59	65
DNG 25025-(G or PW)	1.00 x 1.00	36	157
DNG 50025-(G or PW)	1.00 x 2.00	72	59
DNG 75025-(G or PW)	1.00 x 2.75	110	104
DNG 25037-(G or PW)	1.50 x 1.00	56	157
DNG 37037-(G or PW)	1.50 x 1.50	84	131
DNG 50037-(G or PW)	1.50 x 2.00	114	157
DNG 75037-(G or PW)	1.50 x 2.75	170	66
DNG 50050-(G or PW)	2.00 x 2.00	151	157
DNG 75050-(G or PW)	2.00 x 2.75	225	79
DNG100050-(G or PW)	2.00 x 3.75	302	74
DNG 50075-(G or PW)	3.00 x 2.00	228	65
DNG 75075-(G or PW)	3.00 x 2.75	340	52
DNG100075-(G or PW)	3.00 x 3.75	456	52
DNG 50100-(G or PW)	4.00 x 2.00	305	79
DNG 75100-(G or PW)	4.00 x 2.75	454	52
DNG100100-(G or PW)	4.00 x 3.75	610	39
DNG50125-(G or PW)	4.90 x 2.00	382	52
DNG 75125-(G or PW)	4.90 x 2.75	569	39

(Catalog Number includes cover)

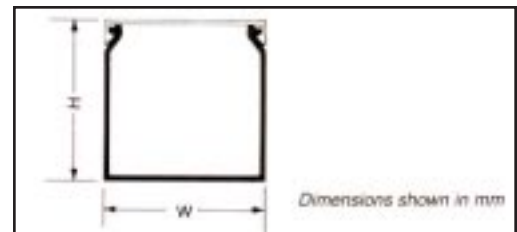

Type HNG - Noryl (Chlorine Free)

Description: For high temperature applications and where a chlorine-free environment is desired. Includes prescored snap-off fingers; snap-on/off cover design; and integral slotted mounting holes. Dimensions identical to DNG duct sizes shown above.

Color: Light Gray

Packaging: Standard length (6'6") 2 meter. Sold complete with covers.

Mechanical Properties

Tensile strength: 9600 psi (675) kg/cm²

Impact resistance: 6.98 ft lbs/sq in.

(<15 cm kg/cm²)

Coefficient of thermal expansion:

59 x 10⁶ per °C.

Electrical Properties

Dielectric strength: 500 volts/mil.

Thermal Properties

Flammability: UL94 V-1

Temperature range: -40°C to 125°C

Material: Noryl (modified Polyphenyl Oxide).

Catalog Number	Dimensions (W x H) Nominal Inches
HNG 37037	1.50 x 1.50
HNG 50037	1.50 x 2.00
HNG 50050	2.00 x 2.00
HNG 75050	2.00 x 2.75
HNG 50075	3.00 x 2.00
HNG 75075	3.00 x 2.75
HNG 50100	4.00 x 2.00
HNG 75100	4.00 x 2.75
HNG 75125	5.00 x 2.75

(Catalog Number includes cover)

