



①





②









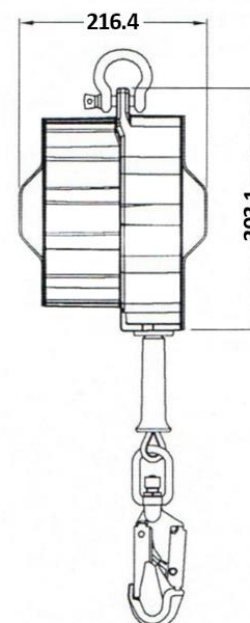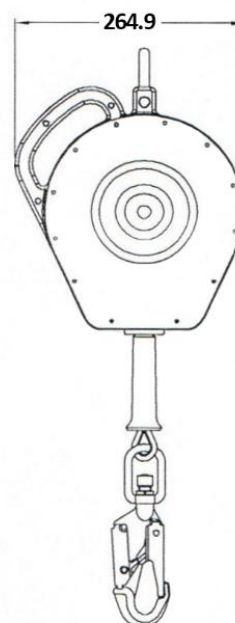



③



④



HS CODE
84798997
CARTON SIZE / PCS.
40 x 30 x 24 cm / 1
AET N°2777/13525-01/E01-01
Satra Technology Europe Ltd., N° 2777, Bracetown Business Park, Clonee, Dublin, D15YN2P, Ireland
MODULE D F114/14003.01
SGS Fimko Oy, N°0598 Takomotie 8, 00380 HELSINKI, Finland
ACKNOWLEDGEMENT OF RECEIPT N°1120/1/2020 (ATEX)
Technická Inšpekcia, a.s. N°1354 Trnavská cesta 56, 821 01 Bratislava, Slovenská Republika


REF.	FA 20 410 20
LG. 	20 m
KG	MAX. 140 KG
CE	EN 360:2002
MAT. 	Polyamide 6 - 30% fiber glass /   Ø 4.5 mm
	 with fall indicator
	x1
R(kN)	12 kN
	NO
+	IEC 60529  EN 80079-36:2016, EN 80079-37:2016 (ATEX Zone 1)
	11.83 KG



Longueur Poids maxi utilisateur
Length Max. user weight
Longitud Peso máximo del usuario
Lunghezza Peso Max. dell'utente
Länge Höchstgewicht des Benutzers



 Matière carter/câble
Material of casing/wire rope
Material cárter/cable
Material dei carter/Cavo
Material Gehäuse/Seil



Matière connecteur haut / connecteur bas
Material of top connector / bottom connector
Material conector alto / conector bajo
Materiale connettore alto / connettore basso
Material oberes / unteres Verbindungselement



Nombre d'émerillons
Number of swivels
Cantidad de eslabones giratorios
Numero di tornichetti
Anzahl der Wirbel



Indice de protection relatif à l'étanchéité (poussière et eau)
Degree of protection related to sealing (dust and water)
Índice de protección relativo a la estanqueidad (polvo y agua)
Indice di protezione relativo all'impermeabilizzazione (polvere e acqua)
IP-Schutzart (Staub und Wasser)



Homologué pour le travail à proximité d'arêtes vives
Approved for work near sharp edges
Homologado para trabajo cerca de aristas vivas
Omologato per lavoro in prossimità di spigoli vivi
Zugelassen für Arbeiten in der Nähe scharfer Kanten