



# Datasheet

## New 5.0mm Screwless 15A 3 Way

RS Stock 874-5502

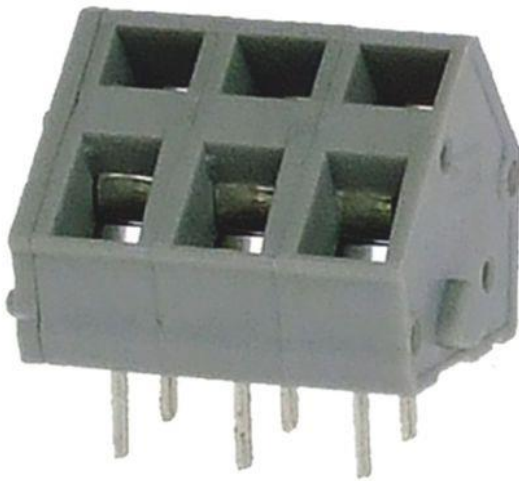

### Dimensions: (mm)

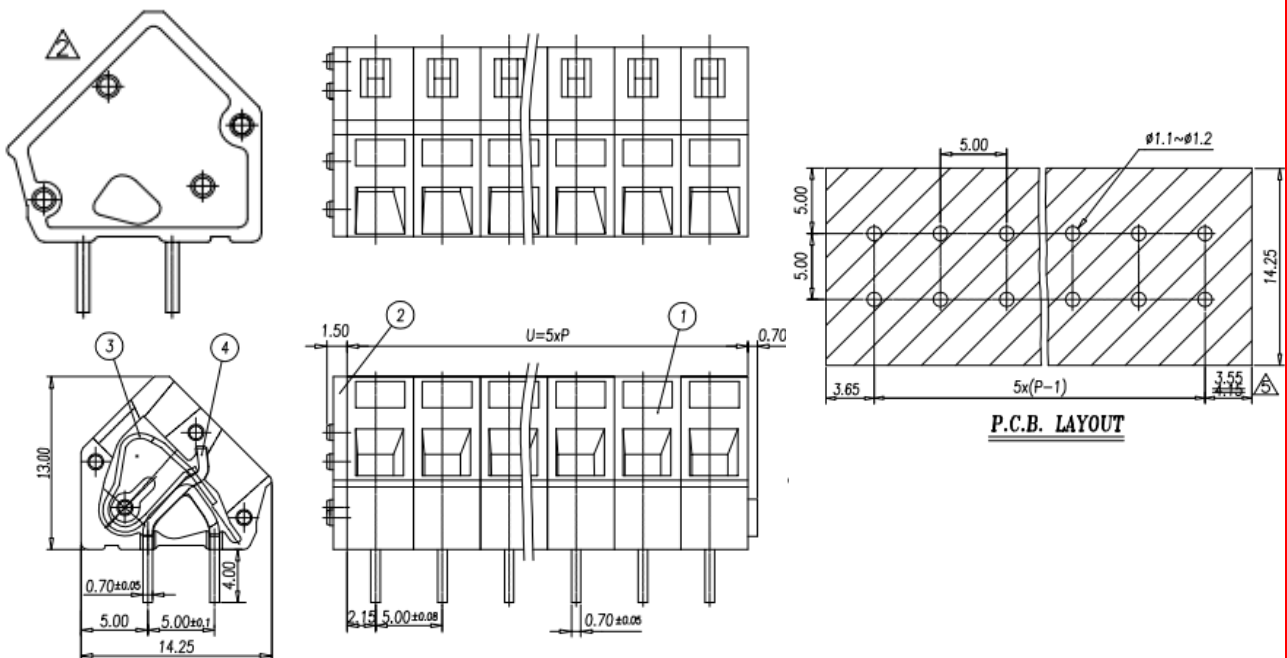



ENGLISH

## Specifications

- Rated Voltage: 300V 15A
- Insulation Withstands Voltage: AC 2500 V/ Min
- Insulation Resistance:  $\geq 500\Omega\text{M}$  or more at DC500V
- Temperature Range:  $-40^{\circ}\text{C} \sim +105^{\circ}\text{C}$
- Suitable Electric Wire: 28~12AWG

## Materials

- Housing: PA66
- Clamp: Stainless Steel
- Solder Pin: Copper
- End Cover: PA66 (VO)
- Solder Pin: Brass