


KEMET Part Number: SCR38-350-1R8B008JH
(UALAG1R8B008J0)

KEMET, SCR38, AC Line Filters, Common Mode, 850 uH

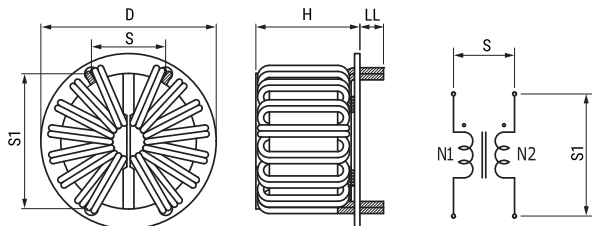

Dimensions

D	53.5mm MAX
T	53.5mm MAX
H	31.5mm MAX
LL	7mm +/-3mm
S	22mm NOM

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	48
Weight:	120 g

General Information

Series:	SCR38
Style:	Through-Hole
RoHS:	Yes
Notes:	Lead Spacing (S/S1) Are For Reference Only.
Miscellaneous:	Temperature Rise Maximum: 65 K

Specifications

Voltage AC:	250 VAC
Inductance:	0.85 mH
Current:	35 A
Temperature Range:	-25/+120°C
DC Resistance:	2.5 mOhms