

Mosaic™ mechanisms

single, multi-support power sockets: German and international standards



772 11



775 02



775 04




775 05



775 06



771 11

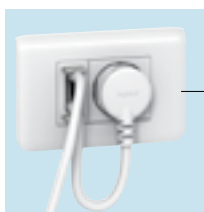

770 80



772 31



775 86



Selection chart for boxes, supports and plates (p. 812-813)

Pack	Cat.Nos	Multi-support single sockets - German standard
		With shutters for child protection (except Cat.No 772 10) For installation in flush-mounting box, surface mounting box, floor box, column module, desktop multi-outlet extension, office module and trunking
10	2 modules 772 10	2P+E without shutters for child protection screw terminals
10	772 11	2P+E - Automatic terminals
10	772 13	2P+E with special tap-off screw and 4 mm ² screw terminals
10	772 45	2P+E angled at 45° - Automatic terminals
10	792 13	2P+E with aluminium finish cover plate screw terminals tamperproof
10	772 14	2P+E - Screw terminals
10	771 10	2P - Automatic terminals
10	772 19	2P+E with cover - Automatic terminals
10	772 12 ⁽¹⁾	2P+E with indicator ⁽¹⁾ - Screw terminals
10	772 16	2P+E green cover plate Automatic terminals
10	772 17	2P+E orange cover plate Automatic terminals
10	772 18	2P+E red cover plate Automatic terminals
10	1 module 771 50	2P ELV screw terminals Automatic terminals

Pack	Cat.Nos	Easy and simple actions 2P+E socket
1	5 modules 772 31	Special for disabled persons 2P+E socket Simple action on the lever allows easy plug-in or unplug

Pack	Cat.Nos	International standard power sockets
		Connection by screw terminals
10	1 module 775 01	Euro-US 2P
10	2 modules 775 02	2P+E
10	1 module 775 03	US 2P
10	2 modules 775 04	2P+E 15 A
10	2 modules 775 05	British 2P+E 13 A
10	1 module 775 10	Italian 2P+E 10 A on line
10	775 11	2P+E 10/16 A
10	2 modules 775 06	Swiss 2P+E type 13 Automatic terminals
10	2 modules 771 11	French 2P+E Automatic terminals
1	1 module 770 80	Anti-extraction module When used with a socket, avoids accidental unplugging of sensitive electrical equipment, by gripping the cord (Ø4 to 8 mm cords) Can withstand an extraction force of 350 N (35 kgs)
1	5 modules 775 86	Shaver sockets IP 24 - IK 04 Conform to EN 60742 and EN 61558-2 Power supply 230 VA - 50/60 Hz and 1 output 120/220 V~. Connection via automatic terminals Equipped with a circuit separation transformer to isolate the user from the mains supply Protected against overloads and short circuits by built-in thermal relay limiting the available power to 20 VA. Insertion of the plug activates the power supply to the transformer With integrated support For flush mounting boxes only, use 2 gang box, 40 mm deep

(1) Indicator Cat.No 676 64 (see p. 546) supplied with the product