

Flat Cable Connectors SEK

- har-mik®
- D-Sub
- InduCom

Applications



Product details

09 18 526 5813
IDC female connector

Termination	Flat cable insulation displacement
Connector size	26 contacts
IDC strain relief clamp	With strain relief
Cover	With an open end cover
Centre polarization	With central polarisation
Performance level	AU-0.76•m [30• Inch]
RoHS compliant	Yes

Available Downloads





Title	Format	
Data sheet	PDF	download
CAD data 2D	DXF	download

Further links


3D-Library




Inquiry

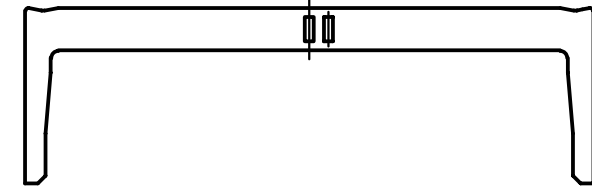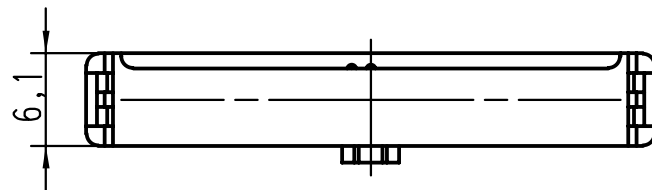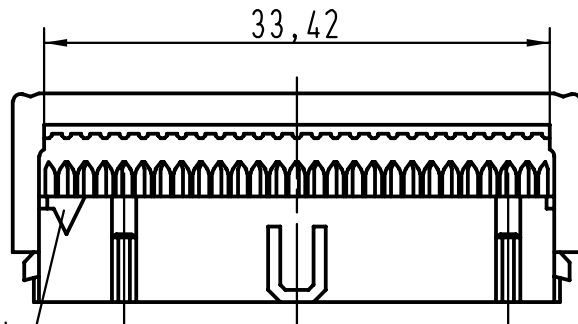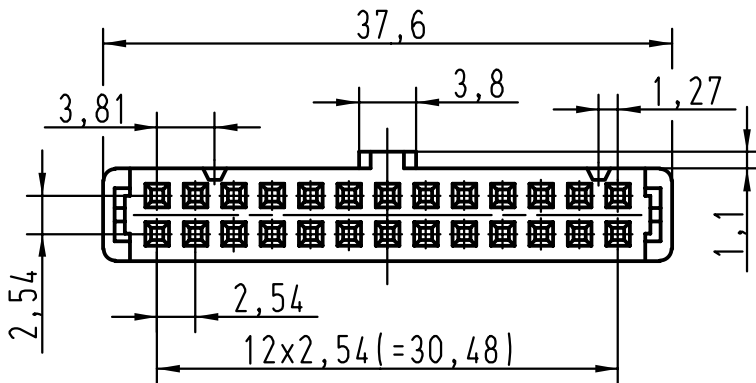

vorverrastet
pre assembled
perassemble

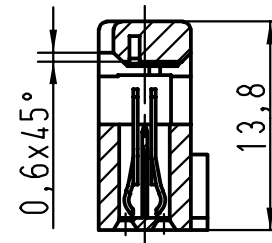

strain relief verrastet
fitted
assemble

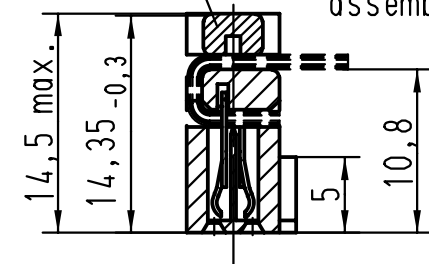

- 1) Markierung erster Kontakt, Ader 1 des Flachkabels
1) Contact no.1, 1st wire of flat cable
1) Contact no.1, repère 1 du câble

				All Dimensions in mm Original Size DIN A 4				Techn. Character.			Nicht tolerierte Masse/ Free size tolerances	
A	09185265813	0,76 µm Au						Detail.	01-FEB-00	Th	Massstab/ Scale 2:1	SEK 18 Female connector 26 poles with central polarisation without cable stop with strain relief
	09185266813	2						Insp.	01-FEB-00	JMV		
	09185267813	3						Stand.				
	Bestell-Nr. Part-No. Reference	Anforderungsstufe performance level Niveau de qualite		26570	01-FEB-00	JB	HARTING EURL F-95972 Paris				TB 0918526X813	
				Mod.	Dat.	Name					Sub.	