


### Deep groove ball bearings, single row, seal on both sides

Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
20	32	7	4,03	2,32	0,104	-	13000	0,018	61804-2RS1

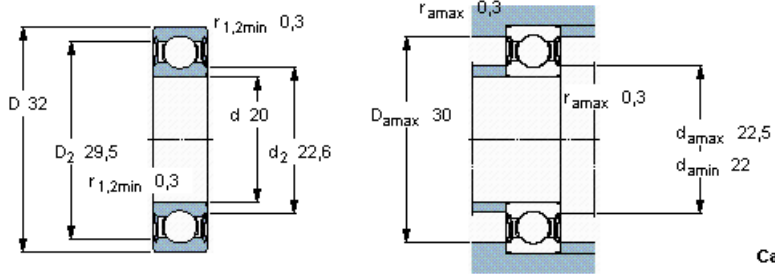

**Calculation factors**

$k_r$  0,015  
 $f_0$  15