


2400·2450·2480·2500 | Mounting brackets **pivoting**


For tight installation conditions

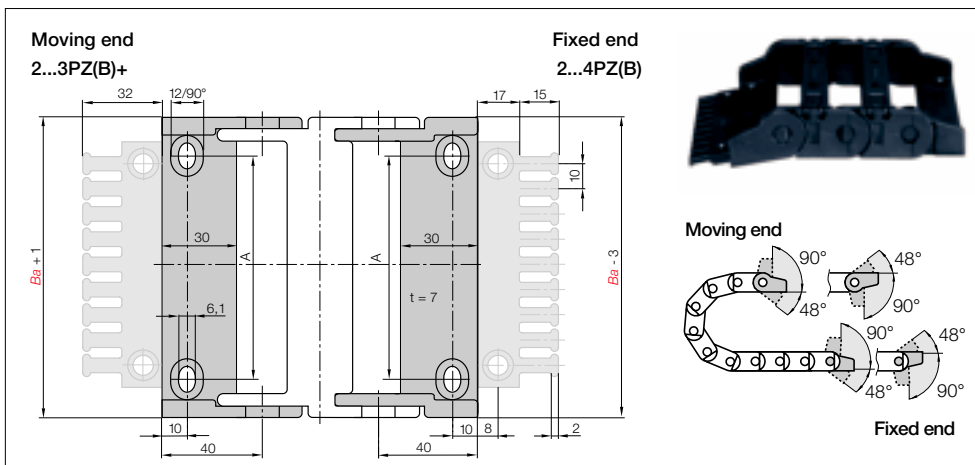

Polymer **pivoting** | Standard - Universal for e-chains® and e-tubes

Recommended for unsupported and gliding applications

For width index	Part No. full set with tiewrap plate	Full set with tiewrap plate + 10 cable tiewraps	Part No. full set without tiewrap plate	Dim. A [mm]	Number of teeth
.02. ▶	2020.34PZB+	2020.34PZBK1+	2020.34PZ+	12	3
.03. ▶	2030.34PZB+	2030.34PZBK1+	2030.34PZ+	25	4
.05. ▶	2050.34PZB+	2050.34PZBK1+	2050.34PZ+	44	6
.07. ▶	2070.34PZB+	2070.34PZBK1+	2070.34PZ+	64	8
.09. ▶	2090.34PZB+	2090.34PZBK1+	2090.34PZ+	77	10
.10. ▶	2100.34PZB+	2100.34PZBK1+	2100.34PZ+	90	10
.12. ▶	2125.34PZB+	2125.34PZBK1+	2125.34PZ+	112	12

 

- Standard
- For tight installation conditions
- Strain relief with detachable chainfix tiewrap plates
- Corrosion resistant
- Variable traverse angle
- Various installation options on the fixed end and/or the moving end

Part No. structure (pivoting)

2020, 34 PZB+ **A1**




Single-part order

Mounting bracket **Moving end**

2020, 3 PZB+ **A1** (preassembled + tiewrap plate)

Mounting bracket **Fixed end**

2020, 4 PZB **A1** (preassembled + tiewrap plate)

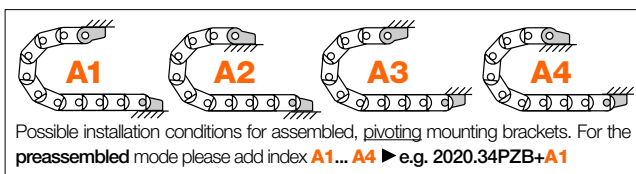

Strain relief e.g. clamps, tiewrap plates, nuggets and plug-in clips are available from stock. The complete chainfix range with order options ▶ from page 10.1