


Datasheet

PVC 5m Long transparent Flexible Ducting Reinforced, 75mm Bend Radius , Applications Food, Liquid, Plants, Spirits

RS Stock number 362-1919

* Suitable for the contact with foodstuff that requires a simulating liquid type A-B-C in accordance with CE 1935/2004. Migration tests made at 40° C for 24 hours.

Ø int. I. D. Innen Ø I.D. mm.	wanddikte wall thickness Wandstärke Vegglykkelse mm.	gewicht weight Gewicht Vekt gr./mtr.	buigradius bending radius Biegeradius Boyeradius mm.	vacuum vacuum Unterdruck Vacum m. H ₂ O	werkdruk working press. Betriebsdruck Arb. trykk bar a 20° C
10	2,75	160	20	9	10
12	2,75	185	25	9	10
14	3	235	30	9	8
16	3	255	35	9	8
18	3	275	40	9	7
20	3	330	50	9	6
25	4,25	530	60	9	5
30	4,25	620	70	9	5
32	4,25	650	75	9	5
35	4,5	770	80	9	4,5
38	4,5	810	90	9	4
40	4,75	880	95	9	4
45	5	1150	110	9	3,5
50	5,5	1270	125	9	3,5
60	6	1700	140	9	3
63	6	1750	150	9	3
75	6,5	2300	200	9	2
80	7	2600	220	9	2
90	7	3000	260	9	2
100	7	3350	300	9	2

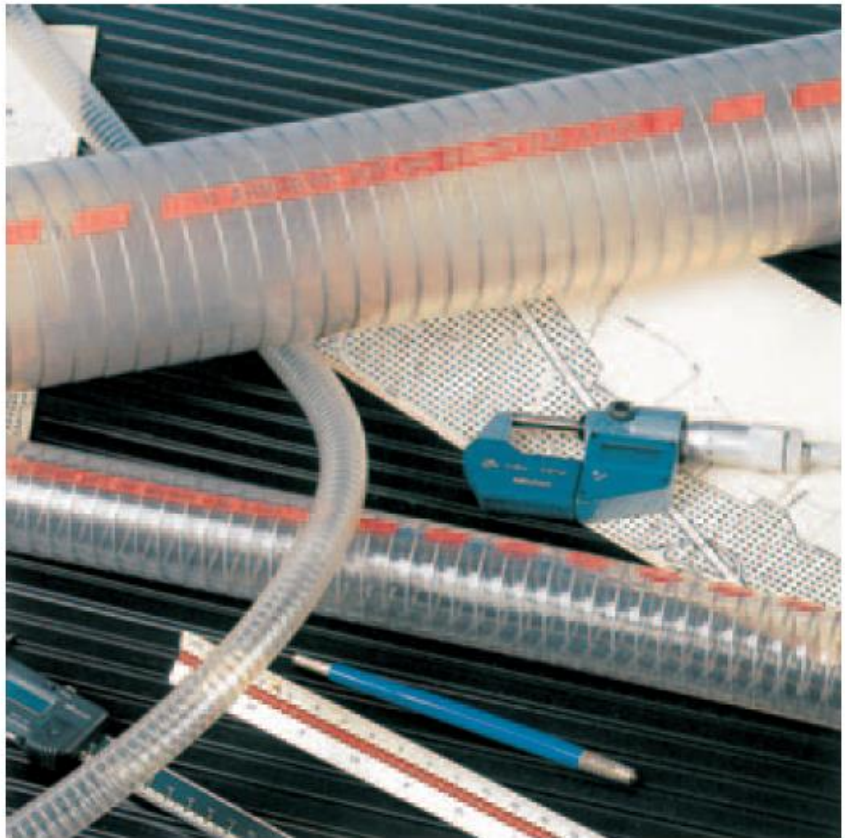

Zeer flexibel, gladde binnen- en buitenwand. Temperatuur bereik: -5° + 65°C.
 Very flexible, smooth inside and outside. Temperature range: -5° C +65° C.



Sehr flexibel, innen und außen glatt. Temperaturbereich: -5° C +65° C.
 Superelastisk og slitesterk slange. Temp.område: -5° C +65° C.
 Næringsmiddelkvalitet.

Zuiging en doorvoer van vloeistoffen, vloeibare levensmiddelen drinkwater, tot 28% alcoholhoudende dranken. Uitstekend geschikt voor installaties waar flexibiliteit, doorzichtigheid, kleine buigradius en hoge prestaties vereist worden.

Suction and delivery of liquids, food liquids, drinkable water, spirits to 28%. It's particularly suitable for plants where flexibility, transparency, narrow bending radius and superior performances are requested.

Saugen und Durchleiten von Nährflüssigkeiten, Trinkwasser und alkoholischen Getränken bis 28%. Besonders geeignet für Anlagen, wo Biegsamkeit, Durchsichtigkeit, enger Biegeradius, höhere Leistungen beim Durchleiten verlangt sind.

Lett sugе-/trykkslange for næringsmiddelindustri, granulat og transport av flytende væske hvor ekstraordinær liten bøyeradius er viktig. Alkoholbestandighet 28%.

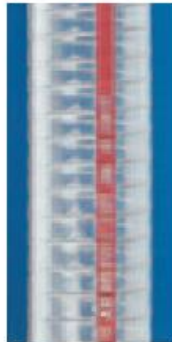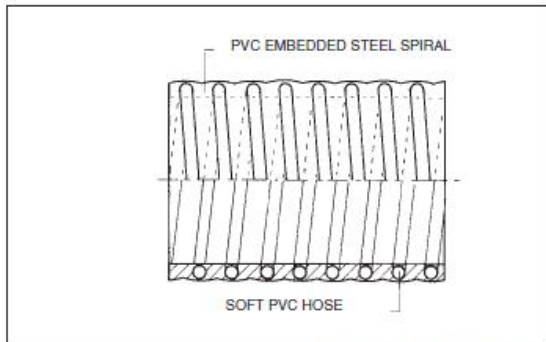

Zachte transparante PVC slang met ingesloten stalen spiraal met enge spoed.

Soft clear PVC with embedded reduced pitch harmonic steel spiral.

Aus weichem kristallklarem PVC mit eingebetteter Stahldrahtspirale mit verringerter Spiralsteigung.

PVC inn- og utvendig. Stålspiral med spesielt liten Stigningsvinkel. Glatt inn- og utvendig. Transparent.