



Datasheet

Stock No: 748-2165

ENGLISH

RS Pro Orange Equipment Wire, 0.5 mm² CSA , 1000 V 20 AWG, 500m




BS 4808

Cable Construction

Conductor	Tinned Copper
square(mm ²)	0.5
Construction	T0.2±0.008×16
Standard Dia.(mm)	0.92
Insulation	PVC
Thickness	0.3
Insulation Dia.(±0.1mm)	1.60

Design

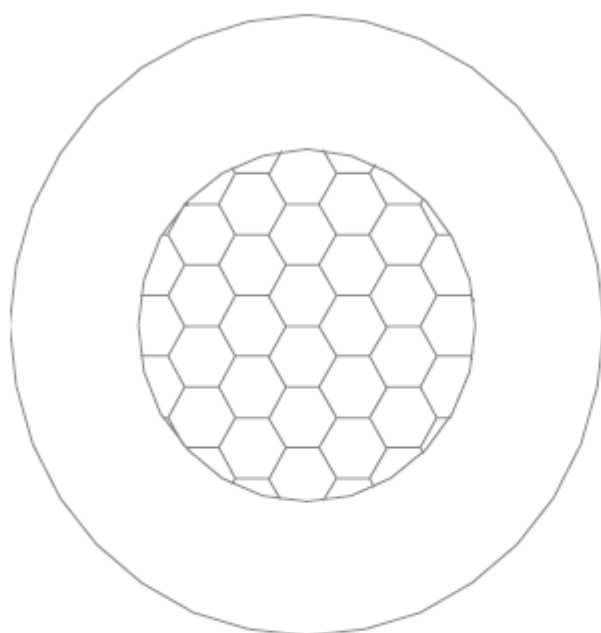

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<37.7
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1000