

Hydroproof 2 - T8 Polycarbonate magnetic ballast

Hydroproof 2 PC 158 T8 LLB NC

0045340



Range features

- Body made from extremely resistant glass-reinforced polyester (SMC)
- Protection against chemicals (Please contact your local sales office for full listing)
- User-friendly and long lasting materials
- Diffuser made of High Quality PolyStyrene (HQPS) or polycarbonate with internal prism system for high light output and broad light dispersion
- Stainless steel closure clips ensure permanent pressure between diffuser and housing to guarantee IP rating



PRODUCT OVERVIEW

Ordering number	0045340
EAN code	54 10288453408
Certifications	D-mark, ENEC
Mount	Ceiling surface
Housing	Glass fibre reinforced polyester
Voltage (V)	230
Lamps	1 x 58W T26 G13
Colour	Grey
IP rating	67
IK rating	8

Hydroproof 2 - T8 Polycarbonate magnetic ballast

Hydroproof 2 PC 158 T8 LLB NC

0045340

DATA TABLE

General data

Ordering number	0045340
EAN code	5410288453408
Certifications	D-mark, ENEC
Mount	Ceiling surface
Notes	Non compensated.
Long description	Body made from extremely resistant glass-reinforced polyester (SMC). Protection against chemicals (Please contact your local sales office for full listing). User-friendly and long lasting materials. Diffuser made of High Quality PolyStyrene (HQPS) or polycarbonate with internal prism system for high light output and broad light dispersion. Stainless steel closure clips ensure permanent pressure between diffuser and housing to guarantee IP rating
Product name	Hydroproof 2 PC 158 T8 LLB NC
Control gear availability	Included
Control gear mounting	Integral
Control gear type	Magnetic
Environment	Interior
General application	Car wash, Chemical industries, Mechanical industries, Technical rooms
Housing	Glass fibre reinforced polyester
Special environment	Clean room, Waterproof
Sales pack quantity	1

Optical data

Distribution type	Symmetric
--------------------------	-----------

Electrical data

Voltage (V)	230
Lamps	1 x 58W T26 G13
Leading trailing edge	No
Number of heads	1
Total number of lamps	1

Hydroproof 2 - T8 Polycarbonate magnetic ballast

Hydroproof 2 PC 158 T8 LLB NC

0045340

Physical data


Weight (kg)	3.70
Colour	Grey
Lamp included	No
Height (mm)	108
Width (mm)	102
Length (mm)	1612
IP rating	67
IK rating	8
Diffuser finish	Prismatic
Diffuser material	Polycarbonate
Emergency	Without
Single package dimensions (L x W x H) (cm)	169.00 x 11.00 x 12.00
Outer package dimensions (L x W x H) (cm)	169.00 x 11.00 x 12.00

Hydroproof 2 - T8 Polycarbonate magnetic ballast

Hydroproof 2 PC 158 T8 LLB NC

0045340

PHOTOMETRY

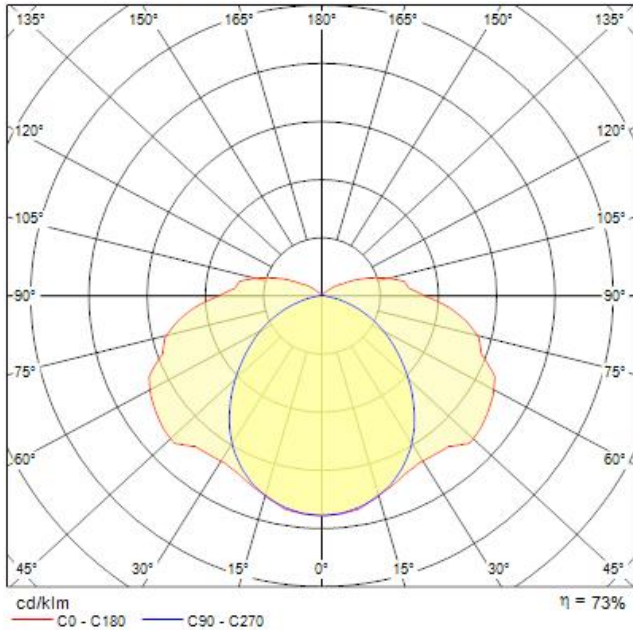


Distance [m]	Cone diameter [m]	E(0°)	E(C90)	E(C0)	Illuminance [lx]
0.5	1.14 35.80	3143	48.8°	88.4°	449 0
1.0	2.28 71.60	786	48.8°	88.4°	112 0
1.5	3.43 107.40	349	48.8°	88.4°	50 0
2.0	4.57 143.20	196	48.8°	88.4°	28 0
2.5	5.71 179.00	126	48.8°	88.4°	18 0
3.0	6.85 214.80	87	48.8°	88.4°	12 0

Distance [m] Cone diameter [m] Illuminance [lx]
 — C0 - C180 (Half beam angle: 176.8°)
 — C90 - C270 (Half beam angle: 97.6°)

TECHNICAL DRAWINGS

Dimensions (mm) Weight (Kg)

Model T8	Model T5	L	W	H	F	Clips	Kg
1 x 18W	1x14/24W	702	102	108	500	6	1.9
1 x 36W	1x28W	1312	102	108	800	8	2.8
1 x 58W	1x35/49W	1612	102	108	1100	10	3.7
2 x 18W	2x14/24W	702	172	108	500	6	1.9
2 x 36W	1x54W /2x28W	1312	172	108	800	8	2.8
2 x 58W	1x80W /	1612	172	108	1100	10	3.7

 

ENERGY LABEL

Hydroproof 2 - T8 Polycarbonate magnetic ballast

Hydroproof 2 PC 158 T8 LLB NC

0045340

