


Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass lb	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
in			lbf		lbf	r/min			-
0,3937	0,748	0,1969	310	132	5,6	80000	38000	0,0121	61800-2Z

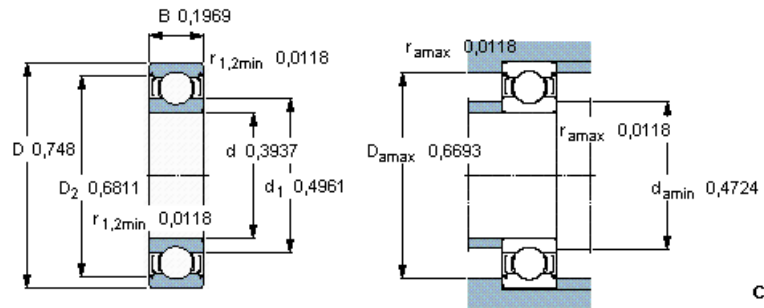

Calculation factors

k_r 0,015

f_0 9,4