


# REXEL BINDING MACHINES

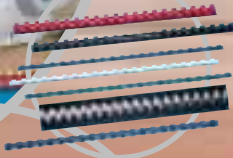

# Rexel Business Machines

*Your No. 1 partner  
for document presentation,  
protection and security*

ACCO, the world-leading office products company,  
has the most powerful brand portfolio in the business –  
including Rexel Business Machines.

All around the world, Rexel, Nobo, Kensington,  
Twinlock, Swingline and Wilson Jones help to put people  
in control of their workspace.

## No.1 for Experience and New Ideas

For more than 50 years Rexel have been creating and building products wholly responsive to their users' needs. An unusual blend of engineering skills, innovation and classically simple design has produced many firsts in binding, laminating and shredding. Today, it produces products that take both form and function to new heights.

## No1 for Style and Innovation

For many people, Rexel products mean style and innovation. As brand leaders they dominate a crowded market through the quality of their design and the unique features they offer to the user.

We are always looking for new ways of thinking, always moving away from the commonplace in search of new ideas.

The new Rexel binder range brings together a host of new ideas and features: all are about improved performance, about working more simply, about making life easier for the user.

## No1 for Reliability

As we see it, to be the best we must also be the most reliable. Skilled engineering, new ideas and superb design all combine with one purpose – to do the job better. And to be there when needed. That's reliability. That's what you get from products that perform.



# COMB BINDING

Of the many binding systems available, comb binding is by far the most popular. Quick and simple, comb binding suits a wide variety of user needs. It also offers total flexibility, and you can bind the smallest document or a 450 page report with ease.

Comb binding is also a very practical binding method. Comb bound documents open out completely flat so they are ideal for presentations and easy to photocopy. The pages are completely secure yet easy to update, as sheets can be added or deleted when required.

Rexel comb binders make life even easier for you. They punch many more pages than other systems, yet require less effort. Documents can be bound much more quickly too, because of the unique, separate comb opening mechanism. The robust, all metal chassis and mechanism means you can use a Rexel comb binder day after day with superb results every time.

Rexel offers a comb binding system to meet every binding requirement, from a compact budget machine to the convenience of electric punch models. All will create professional documents in a matter of minutes.



## Comb Binder overview


Model	Code	Max Punch Capacity (sheets)	Max Binding Capacity (sheets)	Max Comb Size	Formats	Adjustable Edge Guide	Comb Size Guide	Adjustable Margin Control	Punch Selection	Dual Binding	TIPS Punching System
Bindmate	4490000	6	40	8mm	A4	-	-	-	-	-	-
CB205	2100405	8	140	16mm	A4	yes	yes	-	-	-	-
CB255	2100642	15	175	20mm	A4	yes	yes	-	-	-	-
CB305	2100565	15	175	20mm	A4	yes	yes	-	-	-	-
CB355	2100566	25	450	50mm	A4	yes	yes	-	-	-	yes
CB355E	2100567	25	450	50mm	A4	yes	yes	-	-	-	yes
CB405	2100568	30	450	50mm	A4,A5	yes	yes	yes	yes	yes	yes
CB405E	2100569	30	450	50mm	A4,A5	yes	yes	yes	yes	yes	yes

## Comb & Wire Binding

### CB405

Fully featured office model, providing both regular plastic comb binding and also wire binding for fast A4 binding in the general office.

- Features the 'Flowline' concept for faster operation
- Reselectable punches handle all documents up to A4 size
- Translucent cover keeps work area clean when not in use, and provides support for pages being punched
- Punches up to 30 sheets each time
- **TIP SYSTEM** punch system provides better quality paper punching with less effort
- Binds A4 documents up to 450 pages
- Uses all sizes of plastic combs from 4.5mm to 50mm
- Binds A4 documents up to 120 pages using 20 loop wire elements
- Uses all 20 loop wire elements from 6mm up to 12.5mm
- Precision edge guide adjusts to ensure accurate alignment
- Document measure to determine which comb size to use
- Margin is adjustable to suit the size of comb being used
- Wire clamp is protected for safer operation
- Patented 'Lowline' comb grip system for greater safety
- Plastic combs are opened with the new 'simply click' system. Two knobs are fitted to suit LH or RH use

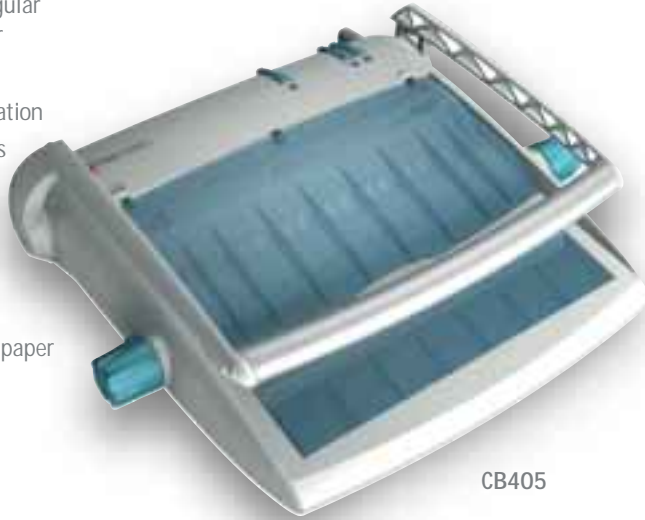

CB405

- High capacity waste container requires emptying less frequently
- Full width punch handle doubles as a carry handle when locked
- May be stored vertically to save space
- Includes starter kit

Code: 2100568

### CB405E

All the performance and features of the CB405 with Electric Punching

Code: 2100569



CB405E



Binds with Plastic AND Wire



Select punches for paper sizes



Adjust margin to match comb size



Convenient storage



Easy action comb opening

## Comb Binding

### CB355

High performance office model, featuring the 'Flowline' concept for faster A4 binding in the general office.

- Translucent cover keeps work area clean when not in use, and provides paper support during the punching process
- Punches up to 25 sheets each time
-  punch system provides better quality paper punching with less effort
- Binds A4 documents up to 450 pages
- Uses all sizes of plastic combs from 4,5mm to 50mm
- Precision edge guide adjusts to ensure accurate alignment
- Document measure to determine which comb size to use
- Covered storage tray keeps plastic binding combs ready for use
- Patented 'Lowline' comb grip system for greater safety
- Plastic combs are opened with the new 'simplyclick' system
- High capacity waste container requires emptying less frequently
- May be stored vertically to save space
- Includes starter kit

Code: 2100566

### CB355E

All the performance and features of the CB355 with Electric Punching, featuring the "Flowline" concept for fast binding in the general office.

Code: 2100567



Flowline concept for easier and faster binding

### CB305

Full sized office model, featuring the 'Flowline' concept at a practical price for the home and small office.

- Punches up to 15 sheets each time
- Binds A4 documents up to 175 pages
- Uses all sizes of plastic combs from 4,5mm to 20mm
- Precision edge guide adjusts to ensure accurate alignment
- Document measure to determine which comb size to use
- Storage tray keeps plastic binding combs ready for use
- Patented 'Lowline' comb grip system for greater safety
- Plastic combs are opened with the new 'simplyclick' system
- High capacity waste container requires emptying less frequently
- May be stored vertically to save space
- Includes starter kit

Code: 2100565



CB355



CB355E



CB305


## Comb Binding

### CB255 Desktop Binder

A highly portable compact machine designed for the home and office.

- Punches up to 12-15 sheets at a time
- Binds documents up to 175 sheets
- Uses plastic combs up to 20mm
- Easy to grip carry handle
- Removable Punch handle can be stored neatly in the base
- Adjustable edge guide for accurate edge alignment
- Starter kit included

Code: 2100642

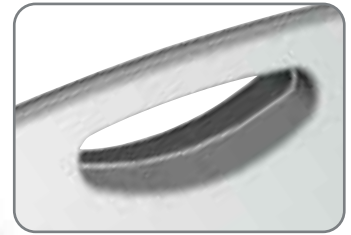

Easy to carry

### CB205 Compact Binder

An easy to use binding machine designed for A4 documents.

- Punches up to 8 sheets at one time
- Binds documents up to 140 pages
- Uses plastic binding rings up to 16mm diameter
- Adjustable edge guide for paper not exactly A4
- Includes starter kit

Code: 2100405



CB255

CB205

### BindMate Personal Binder

For the home, school and office.

- Punches up to 6 sheets at a time
- Binds up to 40 sheets with 6 or 8mm combs
- Unique quick punch action
- Paper positioning guide and easy action comb opening
- Includes starter kit

Code: 4490000



BindMate

# WIRE BINDING

Wire binding produces professional documents that not only look good but are also very easy to use. Wire bound documents are completely secure yet the pages open easily, can be laid flat or even turned through 360° for easy reference and photocopying. Wire bound documents are smart yet business-like, just the right image for any organisation.

The Rexel range of wire binding systems is highly innovative, combining stylish good looks with exceptional performance. Incorporating the latest wire binding technology, these superb machines are the result of an extensive programme of market research, design and development.

Rexel is the leading brand for advanced binding systems and the wire binding range reflects Rexel's renowned expertise. All Rexel wire binding machines use the international standard 3:1" 34 holes punch pattern so that whatever the binding requirement, Rexel can offer a wire binder to suit. There's also a wide range of complementary binding mechanisms and covers to create individual, easy to use documents.



## Wire Binder overview

Model	Code	Max Punch Capacity (sheets)	Max Binding Capacity (sheets)	Max Wire Size	Formats	Adjustable Edge Guide	Wire Size Guide	Punch Selection	TIPS Punching System
WB605	2100572	15	140	14mm	A4	yes	yes	-	
WB655	2100573	20	140	14mm	A4,A5	yes	yes	yes	yes
WB705E	2100574	25	140	14mm	A4,A5	yes	yes	yes	yes

## Wire Binding

### WB605 Desktop Binder

Performance wire binder featuring 'Flowline' concept for faster A4 binding in the office.

- Punches up to 15 sheets at a time
- Binds up to 140 sheets using all 34 loop wire elements
- Binds documents using up all sizes of wire element up to 14mm diameter
- Precision edge guide adjusts for accurate alignment
- Adjustable document measure
- Unique wire support guide and quick view wire size guide
- High capacity waste container with easy clip release

Code: 2100572



WB605



Paper punching at the press of a button



Easy pre-selection of wire closure

### WB655 Desktop Binder

Fully featured office model featuring Flowline concept for easy A4 wire binding in the general office.

- Punches up to 20 sheets at a time
- Binds up to 140 sheets using all 34 loop wire elements
- Binds documents using up all sizes of wire element up to 14mm diameter
-  Punch System for easier punching
- Precision adjustable edge guide and adjustable document measure
- Selectable punches for different sheet sizes – A4, A5, US sizes
- Pre-selectable wire closure knob for simple wire closure
- High capacity waste container with easy clip release

Code: 2100573




WB655



Easy selection of wire size

### WB705e Electric Desktop Binder

Fully featured electric office model providing fast A4 wire binding with the Flowline concept.

- Punches up to 25 sheets at a time, at the punch of a button
- Binds up to 140 sheets using all 34 loop wire elements
- Binds documents using up all sizes of wire element up to 14mm diameter
-  Punch System for easier punching
- Precision adjustable edge guide and adjustable document measure
- Selectable punches for different sheet sizes – A4, A5, US sizes
- Adjustable closure prevents over-closing
- High capacity waste container with easy clip release
- Foot pedal included for hands free punching

Code: 2100574



WB705E

# THERMAL BINDING

Thermal binding is ideal for all kinds of documents, from staff directories to instruction manuals. It provides permanent protection for all your important reference material and the finished result is extremely smart. Thermal bound documents are neat and flat, making them easy to store or carry around. By choosing covers in

different colours and finishes, you can also create a colour coded library of all your important documentation.

Thermal binding is the ideal binding method when time is limited as it requires no initial preparation. Simply place the loose pages of your document into a thermal cover, wait a few seconds for the binding machine to reach temperature, then place your document inside.

Within seconds you'll have a smart, permanently bound document.

A Rexel thermal binder produces highly professional results with a minimum of effort. It sits neatly on a desktop, ready for use at any time. Using a Rexel thermal binder, you can also bind several documents at the same time, which makes the process even faster and more economical.



## Thermal binder overview

Model	Code Binding	Max Binding Capacity (mm)	Max Binding Capacity (sheets)	Format Cycle	Binding Cycle	Binding Size Periods	Cover Size Guide	'Cycle Complete' Signal	Cooling Support	Document
T70	44044	20	200	A4	fixed	1	-	audio & visual	integral	yes
T300	44048	40	400	A4	variable	5 pre-sets	yes	audio & visual	integral	yes

## Thermal Binding

### T70 Personal Binder

Compact, portable binding machine.

- Binding capacity of 20mm (200 pages)
- 40 second fixed heating period
- Simple to use control panel
- Multi purpose lid for safety and document support
- Compact for easy storage
- Auto shut off

Code: 44044



T70



Easy and simple operation



Cover keeps dust away from heater



Compact for easy storage

### T300 Office Binder

Executive thermal binding machine with unique features for safety, performance and storage.

- Binding capacity of 40mm (400 pages)
- Adjustable heating period for the best binding results
- Document support rail for perfect results
- Audio/visual cycle complete signals
- Integrated document cooling
- Auto shut off

Code: 44048



T300



Binding at the press of a button



Binds several documents at a time

# BINDING SUPPLIES

To complement the Rexel range of innovative binding systems, there's also an impressive choice of binding supplies available to ensure your document presentations communicate the clearest, most effective message from your business!

## Comb Binding Mechanisms

● Designed for use with all standard comb binding machines

Spine thickness	Capacity (Sheets)	Pack size	Colour			
			■	□	■	■
6mm	30	100	45500	45505	45510	45520
8mm	50	100	45502	45507	45512	45522
9.5mm	60	100	45525	45530	45535	45540
12.5mm	95	100	45545	45550	45555	45560
16mm	125	100	45565	45570		
20mm	170	100	45575	45580		
25mm	225	50	45585	45590		
38mm	325	50	45595	45600		
50mm	425	50	45605	45610		
6mm	30	25	45450	45455	45452	45457
8mm	50	25	45460	45465	45462	45467
9.5mm	60	25	45470	45475	45472	45477
12.5mm	95	25	45480	45485	45482	45487

## Wire Binding Mechanisms

● For use with standard A4 3:1" wire binding machines

Spine	Capacity (Sheets)	Pack Size	Colour			
			■	□	■	■
5mm	35	100	47900	47901	47902	47903
6mm	55	100	47920	47921	47923	47924
8mm	70	100	47905	47906	47907	47908
9.5mm	85	100	47925	47926	47927	47928
11mm	100	100	47910	47911	47912	47913
12.5mm	115	100	47930	47931	47932	47933
14mm	130	100	47915	47916	47917	47918
6mm	55	25	49304	49305		
8mm	70	25	49308	49309		
9.5mm	85	25	49312	49313		
12.5mm	130	25	49321	49322		

## 20 Loop Silver Wire

● For use with comb binding format (CB405 (E))

Spine Width	Capacity (Sheets)	Pack Size	Silver
8mm	50	100	2100588
12.5mm	95	100	2100590



## Comb Binding Selection Pack

A convenient pack of assorted A4 combs and covers in a range of colours to produce up to 15 comb bound documents.

Code: 45730



## Comb Binder Office Selection Unit

An attractive, sturdy, three drawer re-usable unit with a selection of A4 clear and coloured leathergrain covers and 100 plastic combs in an assortment of sizes.

Code: 2100212



## Slide Binding Strips

Quick and easy way to present your documents without using a binding machine.



Spine Width mm	Capacity (Sheets)	Pack Size	Colour				
			■	□	■	■	Clear
5	15	25	46000	46001	46002	46003	46015
7	30	25	46005	46006	46007	46008	46009
10	50	25	46010	46011	46012	46013	46014

## Binding Accessories

### Clear and Colour Tinted Covers

The popular choice for all reference documents. Spill and tear-resistant covers available in three thicknesses and six colours including clear.



\*Pre-punched for comb binding

Pack size	150 micron		200 micron						250 micron		
	Clear	Super Clear	Clear PVC	Clear Polyprop						Clear	Super Clear
100	48301		48302	2100536	4163707	4163703	4163735	4163704	4163717		
50	41600	41601								41605	41606
50*	41604										
20	46260		7700004								

### Leathergrain and Gloss Finish Covers

Superior A4 binding covers with a rich, leathergrain or strong, satin gloss finish. Available in a variety of colours.



Leathergrain	Colour									
Pack size										
100	46300	91486	91483	91484	91485	91487	4626804	4626825	4626807	91488
100	46780	46781	46783	46782	46784	46785	46788	46786	46787	4168917
50	46700	46710	46730	46720	46740					
50	46705	46715	46735	46725	46745					
20	46262	46264	46261	46263		7700000				
40	7700001	46266	46265	7700002		7700003				

Gloss						
100	48900	4830001	4830006	4830003	4830005	4830020
100	2100052					
50	46800	46790		46810		
50	46805					

### Thermal Binding Covers

For use with thermal binding machines to create permanent book-like documents.



Spine	Capacity (sheets)	Pack size	Colour		
1.5mm	15	25	45445	45822	45829
3mm	30	25	45440	45823	45830
6mm	60	25	45442	45824	45831
9mm	90	25	45448	45825	45832
12mm	120	25	45443	45826	45833
15mm	150	20	45820	45827	45834
18mm	180	20	45836	45828	55835
20mm	200	20	45821		

### Wrap Binding Covers

Wrap around covers for use with combs and wires up to 12.5mm dia. to produce a superior 'Book Bound' appearance concealing the binding mechanism.



Pack size	Colour	Code
20	Blue Board	2100166
20	Ivory Board	2100167
25	Matt Clear	2100222



**ACCO UK & International**

Gatehouse Road  
Aylesbury  
Bucks. HP19 3DT  
Great Britain  
☎ 01296 397444 ☎ 01296 489539

**ACCO Polska**

Falenty Nowe  
ul. Rozy 11  
05-090 Raszyn  
Polska  
☎ 022 720 5300 ☎ 022 720 3458

**ACCO Benelux**

Peppelkade 64  
3992 AK Houten  
Nederland  
☎ 030 634 6060 ☎ 030 634 6070



ACCO EUROPE  
www.accoeurope.com

**ACCO France**

Rue Ampère BP33  
91430 Igny Zai  
France  
☎ 01 69 85 8900 ☎ 01 69 85 8992

**ACCO Italia**

10036 Settimo Torinese (TO)  
Via Regio Parco 108 / bis  
Italy  
☎ 011 896 1111 ☎ 011 896 1234

**ACCO Deutschland**

Hetzel GmbH & Co. KG  
Schorndorfer Str. 69  
D-73635 Rudersberg-Steinberg  
Germany  
☎ 0049 0 7183 3003-54  
☎ 0049 0 7183 3003-52  
Email: hotline@accodeutschland.de

**ACCO Hungária KFT**

Óscai út 4  
1239 Budapest  
Hungária  
☎ 00 36 1 2 83 16 45  
☎ 00 36 1 2 83 09 28

**ACCO Ireland**

Clonshaugh Industrial Estate  
Clonshaugh  
Dublin 17  
Republic of Ireland  
☎ 00 353 1 8164300  
☎ 00 353 1 8164302  
**ACCO North America**  
300 Tower Parkway  
Lincolnshire  
IL 60069-3640  
U.S.A.  
☎ 847 541 9500 ☎ 847 419 4139

**ACCO Česká Republika**

Hetzel GmbH & Co. KG  
Kapitána Sochora 2400  
39003 Tábor  
Česká Republika  
☎ 0 04 20 38 18 94 00  
☎ 0 04 20 3 61 23 11 05

**ACCO Nordic**

Kanalvagen 10c, 9tr  
194 61 Upplands Vasby  
Sweden  
☎ 08 59 00 4244 ☎ 08 59 00 4110

**ACCO Canada**

Acco Canada Inc.  
501 McNicoll Avenue  
Ontario  
☎ 416 499 1000 ☎ 416 499 0757