


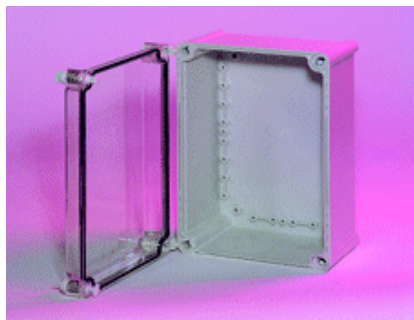

This is a sample photo.

**ORDER SYMBOL:** SC 3819 18 TII

EL.number

**EAN:** 6418074036551

Sweden:

Denmark:

Finland: 3422527

**INCLUDING:**

Cabinet body, cover, hinges, quick-lock screws, and mounting screws.


**APPROVALS:**

USA: NEMA 4, 4X, 12; UL 94-V0

EURO: IP 65; UL 94-V0

OTHERS: IEC 529, CE, EEI, SETI 163458-01

# FIBOX SOLID SC II

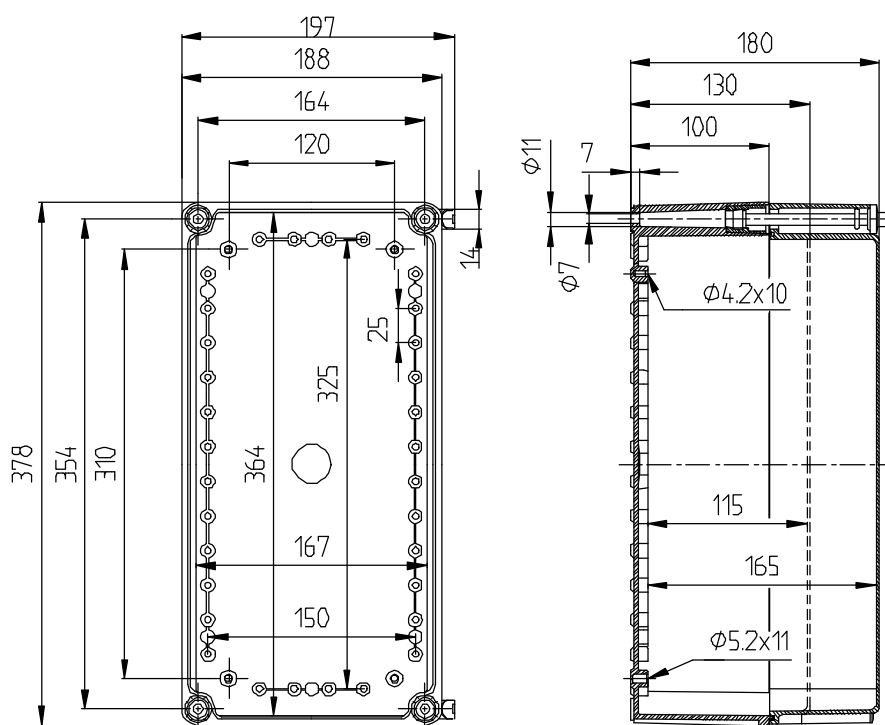

### TECHNICAL INFORMATION:

Standard colour: RAL 7035

Ingress protection: IP 65 (IEC 529)

Flame resistance:

Temp.range in cont. use:      Max. +80 °C

Temp. range of material: - 40 °C - + 120 °C

## ACCESSORIES

|                   |          |               |          |
|-------------------|----------|---------------|----------|
| DIN-Rail          | EKV 12   | Earth bar set | MR 26059 |
| DIN-Rail          | EKV 14   |               |          |
| DIN-Rail          | EKV 22   |               |          |
| DIN-Rail          | EKV 24   |               |          |
| DIN-Rail          | EKV 32   |               |          |
| DIN-Rail          | EKV 34   |               |          |
| Corner plug       | MB 10523 |               |          |
| Fastening lug     | MB 10674 |               |          |
| Earth bar support | MB 26069 |               |          |