


Deep groove ball bearings, single row, SKF Energy Efficient (E2) bearings



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
15	42	13	11,4	5,3	0,224	41000	21000	0,082	E2.6302-2Z/C3

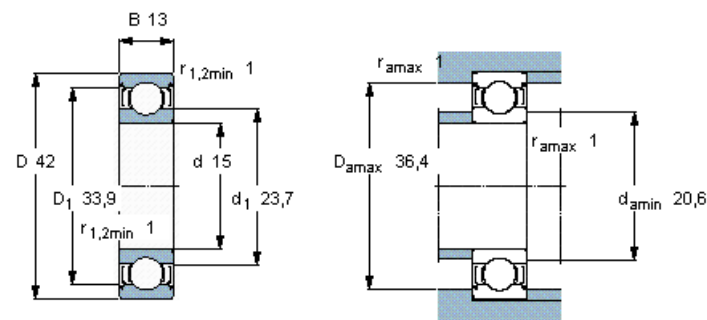

Calculation factors

$k_f = 0,03$
 $f_0 = 12$