




Electrical Commercial and Industrial

MVU18BCX

3M™ Scotchlok™ Butt Connector Vinyl Insulated, 100/bottle, MVU18BCX

3M ID 80611464639 UPC# 00051128588178 3M Product Number 58817 3M Product Number MVU18BCX

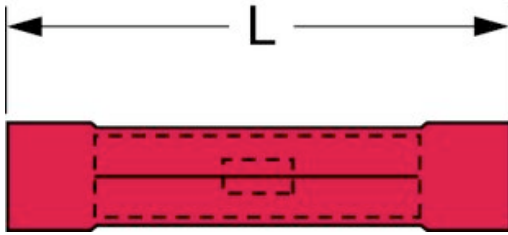

Butt Connector Vinyl Insulated, 100/bottle, MVU18BCX

Overview

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.070 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Scotchlok
China RoHS - Below MCV	Yes
Conductor Sizes	22 - 18 AWG
CSA File Number	LR22190
EU RoHS Compliant	Yes
Insulation Material	Vinyl
Length (L)	1.00 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	100 per bottle
Terminal Style	Standard
Terminal Type	Butt
Thickness	0.030 Inch
UL File Number	E23438

Manufacturing Origin: USA