

Iboco wiring systems feature excellent assembly functionality and are ideal for any type of power and control panel where performance remains unaltered over time even under the heaviest operating conditions. The reliability and durability of these products is guaranteed by a very severe selection of raw materials employed for their production and rigorous process controls. Their superior quality is a guarantee of product compliance with all major national and international standards.

The full range includes control panel trunking with different slot openings, sizes and colours. In addition there are several functional components and accessories available.

IBOCO T1-F RANGE

Iboco T1-F range is ideal for wiring large sized cables usually employed in power panels. Narrow fingers for easier vertical wiring before the cover is mounted, it has correct wire positioning and circuit separation. With a thick side and base, it has a strong construction and maximum application stability, very good holding under heavy wiring and longer durability and reliability. Available in a wide range of heights for space optimisation inside the electric panel.

Recommended fixing method; Iboco rivets or washers. Supplied with lid.


SPECIFICATIONS:

MATERIAL: Rigid Self-Extinguishing PVC

COLOUR: Grey RAL 7030

SERVICE TEMPERATURE RATING: -15°C to +60°C

STANDARDS: CSA, IMQ, UL, R.I.N.A Approved.

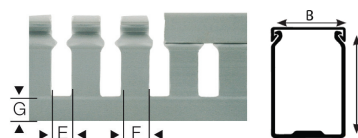

PART NUMBERS:

| PART NO. | BASE x HEIGHT (mm) | DIMENSIONS (mm) | | | SECTION (mm ²) | PACK QTY (m) |
|----------------|--------------------|-----------------|----|----|----------------------------|--------------|
| | | E | F | G | | |
| T1-F 25X80 G | 25 x 80 | 8 | 12 | 16 | 1550 | 48 |
| T1-F 25X100 G | 25 x 100 | 8 | 12 | 16 | 2300 | 16 |
| T1-F 40X80 G | 40 x 80 | 8 | 12 | 16 | 2700 | 32 |
| T1-F 40X100 G | 40 x 100 | 8 | 12 | 16 | 3310 | 16 |
| T1-F 60X80 G | 60 x 80 | 8 | 12 | 16 | 4140 | 24 |
| T1-F 60X100 G | 60 x 100 | 8 | 12 | 16 | 5140 | 8 |
| T1-F 80X80 G | 80 x 80 | 8 | 12 | 16 | 5660 | 24 |
| T1-F 80X100 G | 80 x 100 | 8 | 12 | 16 | 7020 | 8 |
| T1-F 100X80 G | 100 x 80 | 8 | 12 | 16 | 7150 | 16 |
| T1-F 100X100 G | 100 x 100 | 8 | 12 | 16 | 8920 | 8 |
| T1-F 120X80 G | 120 x 80 | 8 | 12 | 16 | 8630 | 16 |
| T1-F 150X100 G | 150 x 100 | 8 | 12 | 16 | 13570 | 8 |



CABLECRAFT
creative wiring solutions



INVESTORS
IN PEOPLE



CABLECRAFT COMPANY

Cablecraft House, Circle Business Centre, Blackburn Road, Houghton-Regis, Bedfordshire, LU5 5DD.

Phone: 01582 606033 • Fax: 01582 606063 • Email: sales@cablecraft.co.uk • Web: www.cablecraft.co.uk

VAT NO. GB 639 920 900 • CO. REG. NO. 2478297