


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
30,162	64,292	21,433	49,5	61	8000	11000	M 86649/2/610/2/QVQ5C

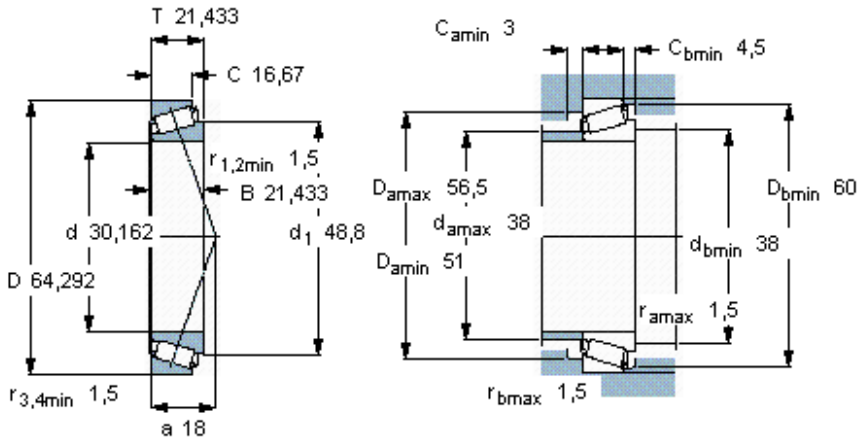

Calculation factors
 $e = 0,54$
 $Y = 1,1$
 $Y_0 = 0,6$