
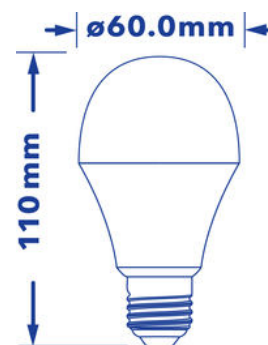


Verbatim LED Classic A E27 6W 2700K Warm White 480 LM


- E27 Socket
- 220 - 240 V Voltage
- 20,000 hours Lifetime
- 85% Energy Saving
- Lumen: 480
- Equivalent to 40W incandescent bulb

Product Number	52600
General Data	
Lamp Socket	E27
Electric Data	
Wattage (W)	6
Wattage Equivalent (W)	40
Voltage (V)	220 - 240 V
Dimmable	no
Power Factor	0.75
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	110
Diameter (in mm)	60
Weight (g)	76
Photometric Data	
Luminous Flux (lm)	480
CRI	≥ 80
CCT (K)	2700
Beam Angle (°)	220
Luminous Efficacy (lm/W)	80
Lifetime (hrs)	20,000
Switching Cycle	100,000

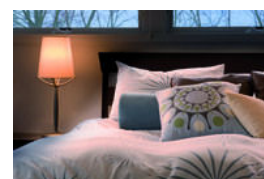


02/07/2014

Photometric Diagrams

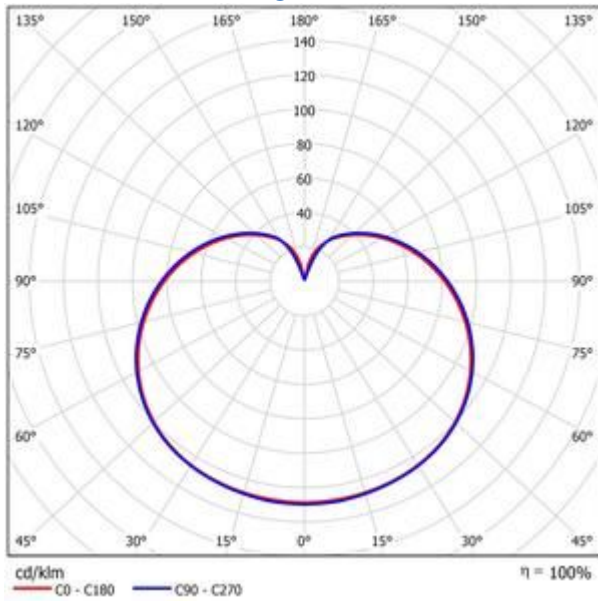

Energy Rating

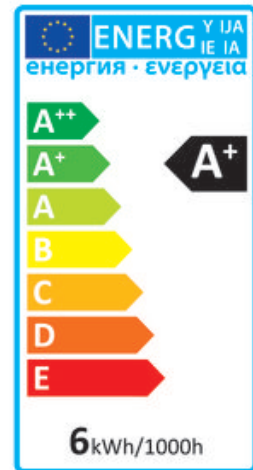

Technical Packaging Details

Barcode

023942526001

EAN 128

(02)00023942526001(37)04(91)204

EAN 14

50023942526006

Pack Dimensions(HxWxL)

178 x 118 x 61

Pack Weight

112

MOQ

4

Carton Dimensions (HxWxL)

195 x 144 x 253

Cartons/Pallet

80

Layers/Pallet

4

Units/Pallet

320

02/07/2014