

**工业以太网**  
**IE-BS-V04P-RJ45-C**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com



PushPull 接插件 符合 IEC 61076-3-106 Var.4 (IEC24702)  
塑料, 带 RJ45插芯

**订货数据**

类型	IE-BS-V04P-RJ45-C
订货号	<a href="#">1963490000</a>
版本	法兰 RJ45, IP 67, 类别4, 耦合, Cat.6A / Class E <sub>A</sub> (IEC 11801 PDAM Am 1.2 2007)
GTIN (EAN)	4032248645589
最小包装数	10 个

## 工业以太网 IE-BS-V04P-RJ45-C

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

# 技术数据

### 尺寸及重量

净重 40.7 g

### 温度

工作温度 -40 °C...+70 °C      存储温度  
 安装温度

### 下载

GOST认证	POCC DE.ME25.B01411.pdf	UL认证	DUXR.E316369.pdf
Attestation of conformity ISO/IEC EN & TIA/EIA Screened Class E Category 6, 3 connector permanent link	ac107534.pdf	Attestation of conformity ISO/IEC EN & TIA/EIA Screened Class E Category 6, 4 connector channel	ac107533.pdf
Attestation of conformity ISO/IEC EN & TIA/EIA Screened Class EA Category 6A, 2 connector channel	ac107535.pdf	Attestation of conformity ISO/IEC EN & TIA/EIA Screened Class EA Category 6A, 4 connector channel	z1755b-07-D.pdf

### PB47 RJ45 I通用参数

外壳基本材料	PA UL 94 V0	密封圈材料	NBR
屏蔽	360° 全封闭外壳	插拔次数	750
插针镀层	镍镀金	物品描述	类别4, 耦合
目录册	Cat.6A / Class E <sub>A</sub> (IEC 11801 PDAM Am 1.2 2007)	端口 2	
端口 1	RJ45	防护等级	RJ45 IP 67


### 标准

连接器标准	IEC 61076-3-106 型号4, IEC 60603-7-51	证书号 (cULus)	E316369
-------	-------------------------------------	-------------	---------

### 分类


ETIM 3.0	EC001121	UNSPSC	30-21-18-17
eClass 5.1	27-26-12-03	eClass 6.2	27-26-12-03
eClass 7.1	27-25-05-04		

### 认证

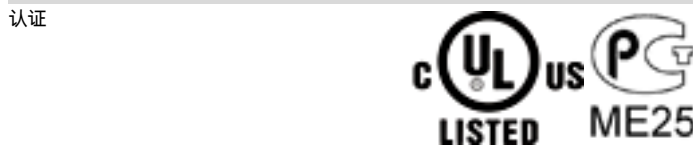

ROHS 一致

**安装开孔**

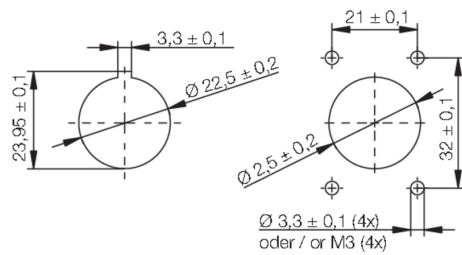

安装截面图：1. 中央螺栓固定 / 2. 用4颗M3螺钉安装时

## 工业以太网 IE-BS-V04P-RJ45-C

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

### 配套的接插件 (完全可插拔)

#### 套件 - RJ45

PushPull 接插件 符合 IEC 61076-3-106 Var.4 (IEC24702)  
 塑料, 带 RJ45插芯



#### 订货数据

类型	订货号	版本	GTIN (EAN)	最小包装数
IE-PS-V04P-RJ45-FH-B	<a href="#">1271240000</a>	RJ45 插头, 无需工具, 类别4, Cat.6A / Class E <sub>A</sub> (IEC 11801 PDAM Am 1.2 2007)	4050118060027	10 个
IE-PS-V04P-RJ45-FH	<a href="#">1963160000</a>	RJ45 插头, 无需工具, 类别4, Cat.6A / Class E <sub>A</sub> (IEC 11801 PDAM Am 1.2 2007)	4032248651665	10 个
IE-PS-V04P-RJ45-TH	<a href="#">1963180000</a>	RJ45 压接插头, 类别4, Cat.6A / Class E <sub>A</sub> (IEC 11801 PDAM Am 1.2 2007)	4032248653973	10 个
IE-PS-V04P-RJ45-FH-BP	<a href="#">1963170000</a>	RJ45 插头, 无需工具, 类别4, 带扭折保护, Cat.6A / Class E <sub>A</sub> (IEC 11801 PDAM Am 1.2 2007)	4032248653980	10 个
IE-PS-V04P-RJ45-TH-BP	<a href="#">1963190000</a>	RJ45 压接插头, 类别4, 带扭折保护, Cat.6A / Class E <sub>A</sub> (IEC 11801 PDAM Am 1.2 2007)	4032248651672	10 个