


Enclosures - IP66 Gemini Range

Surface mounted boards for Distribution and Automation

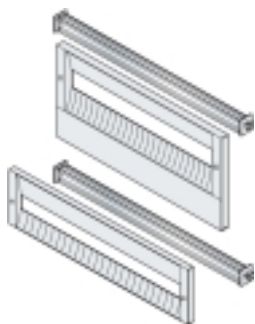

150mm MCB Kit

Size HxW	Size	Modules	Order Code
150 x 250	1	12	1SL0307A00
150 x 375	2	18	1SL0308A00
150 x 375	3	18	1SL0308A00
150 x 500	4	24	1SL0309A00
150 x 500	5	24	1SL0309A00
150 x 750	6	36	1SL0310A00




225mm MCB Kit

Size HxW	Size	Modules	Order Code
225 x 375	2	18	1SL0313A00
225 x 375	3	18	1SL0313A00
225 x 500	4	24	1SL0314A00
225 x 500	5	24	1SL0314A00
225 x 750	6	36	1SL0315A00



Top Hat DIN-Rail

Size W	Size	Modules	Order Code
210	1	12	1SL0290A00
318	2	18	1SL0291A00
318	3	18	1SL0291A00
443	4	24	1SL0292A00
443	5	24	1SL0292A00
663	6	36	1SL0293A00

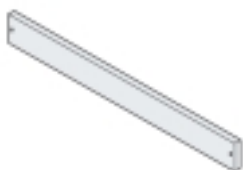

Plain Inner Door 75mm


Size HxW	Size	Order Code	Price
75 x 250	1	1SL0318A00	4.35
75 x 375	2	1SL0319A00	4.96
75 x 375	3	1SL0319A00	4.96
75 x 500	4	1SL0320A00	5.82
75 x 500	5	1SL0320A00	5.82
75 x 500	6	1SL0321A00	6.52

Discount Band A




Enclosures - IP66 Gemini Range

Surface mounted boards for Distribution and Automation

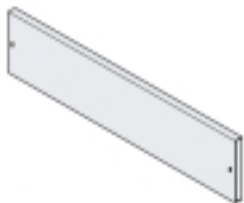


Plain Inner Door 150mm

Size HxW	Size	Order Code
150 x 250	1	1SL0324A00
150 x 375	2	1SL0325A00
150 x 375	3	1SL0325A00
150 x 500	4	1SL0326A00
150 x 500	5	1SL0326A00
150 x 750	6	1SL0327A00

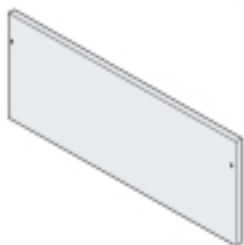


Plain Inner Door 300mm

Size HxW	Size	Order Code
300 x 250	1	1SL0330A00
300 x 375	2	1SL0331A00
300 x 375	3	1SL0331A00
300 x 500	4	1SL0332A00
300 x 500	5	1SL0332A00
300 x 750	6	1SL0333A00

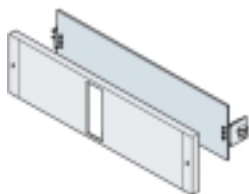

150mm T-Max Mounting Kit

Size HxWxD	Size	Order Code
150 x 370 x 260	2	1SL0336A00
150 x 370 x 260	3	1SL0336A00
150 x 500 x 260	4	1SL0337A00
150 x 500 x 360	5	1SL0337A00
150 x 750 x 360	6	1SL0338A00

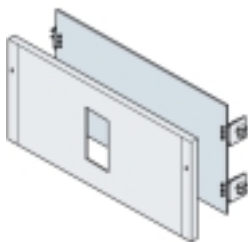

300mm T-Max Mounting Kit

Size HxW	Size	Order Code
300 x 370	2	1SL0370A00
300 x 370	3	1SL0370A00
300 x 500	4	1SL0371A00
300 x 500	5	1SL0371A00
300 x 750	6	1SL0372A00