

This is a sample photo.



ORDER SYMBOL: AL 232018

EL.number **EAN:** 6418074004239
 Sweden: 2536335
 Denmark: 8212004799
 Finland: 3423633

INCLUDING:
 Enclosure body, cover with Neoprene gasket, cover screws, and earth screws.

APPROVALS:
 USA: UL Type 1, 4, 4X, 12, 13 (E75645 Vol.1 Sec.6)
 EURO: IP 67/IP 66
 OTHERS: IEC 529

FIBOX EURONORM II AL

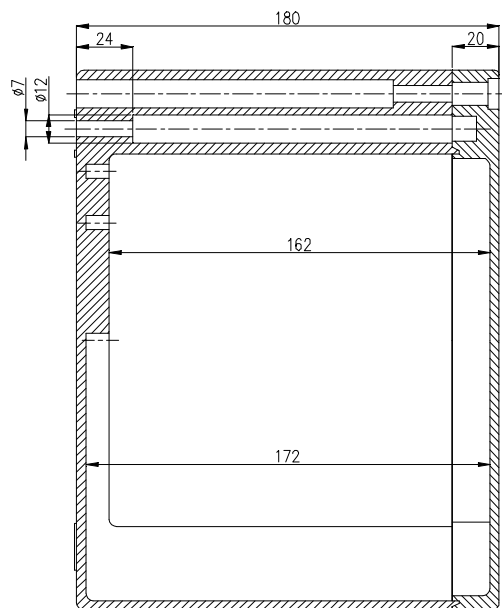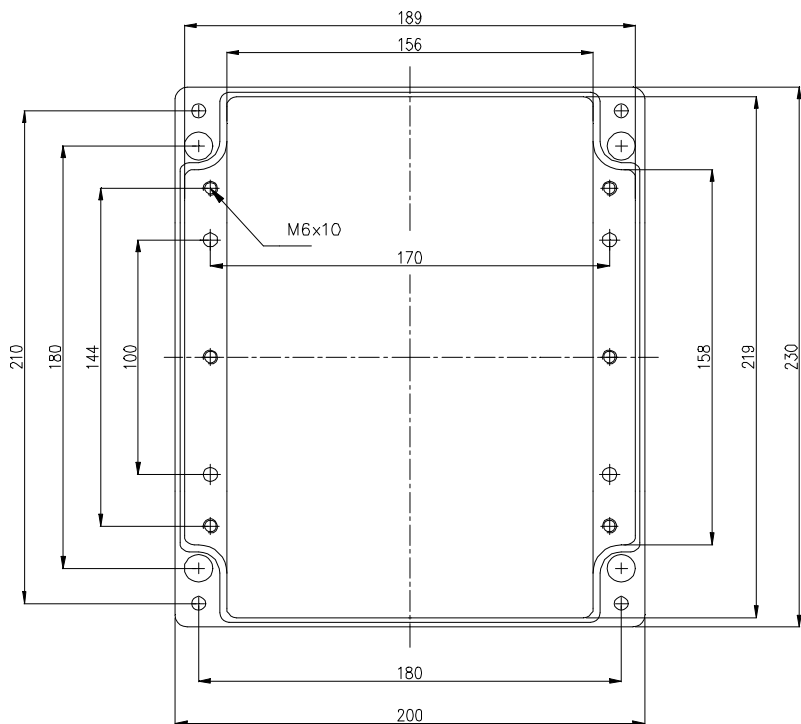

TECHNICAL INFORMATION:

Standard colour: RAL 7001
 Ingress protection: IP 67 (IEC 529)
 Flame resistance:

Temp.range in cont. use: Max. +80 °C
 Temp. range of material: - 50 °C - + 120 °C

ACCESSORIES

DIN-Rail	ARH 12	DIN-Rail	ARH 36	Fastening lug	MRS 28540
DIN-Rail	ARH 16	DIN-Rail	ARH 40	Fastening lug	MRS 28541
DIN-Rail	ARH 1636	DIN-Rail	ARH 60		
DIN-Rail	ARH 1656	DIN-Rail	ARM 0610		
DIN-Rail	ARH 22	DIN-Rail	ARM 0615		
DIN-Rail	ARH 2320	DIN-Rail	ARM 0808		
DIN-Rail	ARH 2328	DIN-Rail	ARM 0813		
DIN-Rail	ARH 2333	DIN-Rail	ARM 0818		
DIN-Rail	ARH 26	DIN-Rail	ARM 0825		