


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
19,05	49,225	18,034	39,1	40	11000	17000	09067/09195/Q

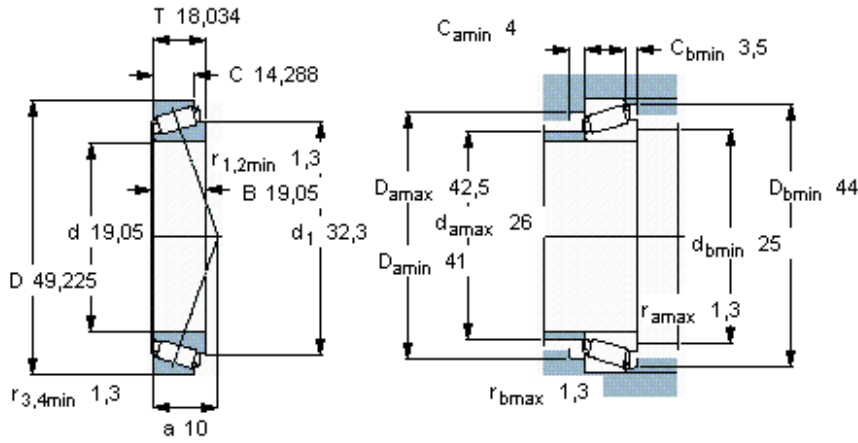

Calculation factors

e 0,27
 Y 2,2
 Y₀ 1,3