




## Electrical Commercial and Industrial

[Products](#) | [Documentation & Literature](#) | [News & Tradeshows](#) | [Support](#)

[United States](#) > [All 3M Products](#) > [Market Segments](#) > [Electronics, Electrical, and Communications](#) > [Electrical Products](#) > [Electrical Commercial and Industrial](#) > [Products](#) >

# 3M™ Highland™ Vinyl Insulated Male Disconnect Terminal MTV18-187Q, AWG 22-18, 25/bag

3M ID 80611602915 UPC# 00051128600306 3M Product Number MTV18-187Q

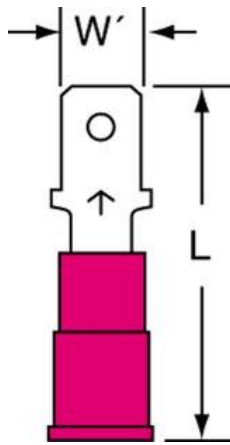

This terminal accepts a wire range of 22-18 AWG, a stud size of .187 and has a case quantity of 10 bags.

[Overview](#) | [Documentation](#)

### Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.08 Inch
Barrel Length	0.24 Inch
Barrel Style	Butted
Brand	Highland
Conductor Sizes	22 - 18 AWG
CSA File Number	LR22190
Fastener Orientation	Male
Insulation Material	Vinyl
Length (L)	0.85 Inch
Mates with Male Tab Width (W')	0.187 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	25 per bag
Pad Width	0.187 Inch
Terminal Style	Standard
Terminal Type	Disconnect
Thickness	0.02 Inch
UL File Number	E70512